




DUAL KEY RUBBER (SJ00W) MICRO-LINK™ CABLE ASSEMBLIES

SPECIFICATIONS			
MATERIALS		ENVIRONMENTAL	
Body	Rubber	Protection	IP67
O-Ring	Nitrile Rubber	Operating Temp	SJ00W: -50°C to 90°C (UL), -34°C to 90°C (CSA)
Contact	Brass, Gold Plated over Nickel	CERTIFICATIONS	
Coupling Nut	Machined Aluminum, Clear Anodized		Recognized, File No. E165657
Cable	#18 AWG SJ00W NBR/PVC 41 x #34 Stranding, 90°C, UL Recognized, CSA Certified		Certified, File No. E165657
Cable Diameters	#18 AWG SJ00W 2/C-.31", 3/C-.33", 4/C-.36", 5/C-.39"	OPTIONS	
ELECTRICAL		Stainless Steel Couplers	
Voltage Rating	250 VAC/300 VDC	Plastic Couplers	
Current	#18 AWG-5A	90 Degree Style Male or Female Bodies	
Contact Resistance	≤5mΩ		

MALE/FEMALE PLUGS

CABLE ASSEMBLY PART NUMBERS						
Number of Poles	Male Contact Rotation	Female Contact Rotation	Wiring Color Code	Length	Wire Gauge (AWG)	Male/Female
2			1-Brown 2-Blue	6 FT/1.8M	#18 (SJ00W)	602K0060C
				12 FT/3.6M	#18 (SJ00W)	602K0120C
				20 FT/6.1M	#18 (SJ00W)	602K0200C
3			1-Green 2-Red/Black 3-Red/White	6 FT/1.8M	#18 (SJ00W)	603K0060C
				12 FT/3.6M	#18 (SJ00W)	603K0120C
				20 FT/6.1M	#18 (SJ00W)	603K0200C
4			1-Red/Black 2-Red/White 3-Red 4-Green	6 FT/1.8M	#18 (SJ00W)	604K0060C
				12 FT/3.6M	#18 (SJ00W)	604K0120C
				20 FT/6.1M	#18 (SJ00W)	604K0200C
5			1-Red/White 2-Red 3-Green 4-Red/Yellow 5-Red/Black	6 FT/1.8M	#18 (SJ00W)	605K0060C
				12 FT/3.6M	#18 (SJ00W)	605K0120C
				20 FT/6.1M	#18 (SJ00W)	605K0200C

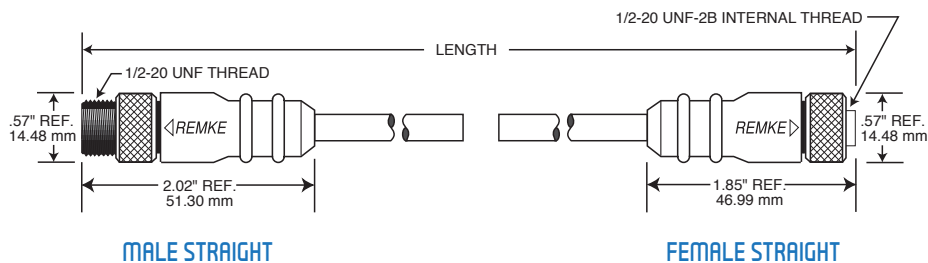

CORD CONNECTORS

WIRE MESH GRIPS

PICO-LINK

MICRO-LINK

ETHERLINK

MINI-LINK

MULTI-PORT BOXES

BUS SYSTEM PRODUCTS