



9 TO 12 POLE PVC MINI-LINK™ PLUG ASSEMBLIES

SPECIFICATIONS

MATERIALS

Body	PVC
Contact Sleeve	Stainless Steel
Contact	Brass, Gold Plated over Nickel
Coupling Nut	Machined Aluminum, Black Anodized
Cable	#16 AWG Type STOW, 65 x #34 stranding 105° C
Cable Diameters	9/C-.62", 10/C-.66", 12/C-.68"

ELECTRICAL

Voltage Rating	600 V
Contact Resistance	≤5mΩ

ENVIRONMENTAL

Protection	IP 67
Operating Temp	-20°C to 105°C


CERTIFICATIONS

 Recognized,
File No. E165657


 Certified,
File No. E165657

OPTIONS

#16 AWG TPE Cable
Stainless Steel Couplers
Plastic Couplers

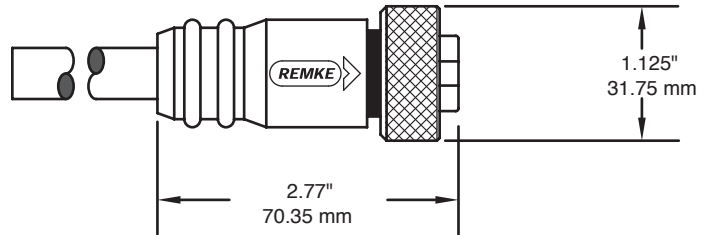

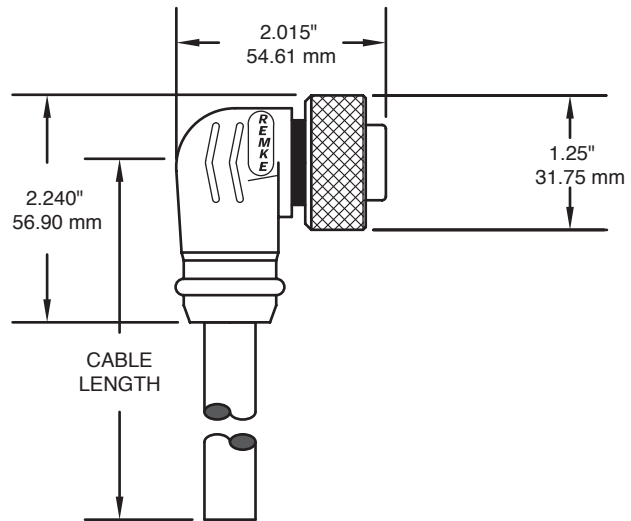


STRAIGHT PLUG






90° PLUG

MALE

PLUG ASSEMBLY PART NUMBERS							
Number of Poles	Male Face View	Wiring Color Code		AMP RTG. @ 600V	Cable Length	Straight	90°
9		1-Orange	6-Red	7A	3 FT	109B0030AP	109D0030AP
		2-Blue	7-Green				
		3-Red-Blk. Tr.	8-White-Blk. Tr.				
		4-Green-Blk. Tr.	9-Black				
5-White							
10		1-Orange	6-Org.-Blk. Tr.	7A	3 FT	110B0030AP	110D0030AP
		2-Blue	7-Red				
		3-White-Blk. Tr.	8-Green				
		4-Red-Blk. Tr.	9-Black				
5-Green-Blk. Tr.	10-White						
12		1-Orange	7-Blue.-Blk. Tr.	5A	3 FT	112B0030AP	112D0030AP
		2-Blue	8-Blk.-Wht. Tr.				
		3-Wht.Blk. Tr.	9-Green				
		4-Red-Blk. Tr.	10-Red				
5-Green-Blk. Tr.	11-White						
6-Org.-Blk. Tr.	12-Black						

FEMALE

PLUG ASSEMBLY PART NUMBERS							
Number of Poles	Female Face View	Wiring Color Code		AMP RTG. @ 600V	Cable Length	Straight	90°
9		1-Orange	6-Red	7A	3 FT	109A0030AP	109C0030AP
		2-Blue	7-Green				
		3-Red-Blk. Tr.	8-White-Blk. Tr.				
		4-Green-Blk. Tr.	9-Black				
5-White							
10		1-Orange	6-Org.-Blk. Tr.	7A	3 FT	110A0030AP	110C0030AP
		2-Blue	7-Red				
		3-White-Blk. Tr.	8-Green				
		4-Red-Blk. Tr.	9-Black				
5-Green-Blk. Tr.	10-White						
12		1-Orange	7-Blue.-Blk. Tr.	5A	3 FT	112A0030AP	112C0030AP
		2-Blue	8-Blk.-Wht. Tr.				
		3-Wht.blk. Tr.	9-Green				
		4-Red-Blk. Tr.	10-Red				
5-Green-Blk. Tr.	11-White						
6-Org.-Blk. Tr.	12-Black						

