




# 9 TO 12 POLE PVC MINI-LINK™ CABLE ASSEMBLIES

SPECIFICATIONS			
<b>MATERIALS</b>		<b>ENVIRONMENTAL</b>	
Body	PVC	Protection	IP 67
Contact Sleeve	Stainless Steel	Operating Temp	-20°C to 105°C
Contact	Brass, Gold Plated over Nickel	<b>CERTIFICATIONS</b>	
Coupling Nut	Machined Aluminum, Black Anodized		Recognized, File No. E165657
Cable	#16 AWG Type STOW, 65 x #34 stranding, 105° C		Certified, File No. E165657
Cable Diameters	9/C-.64", 10/C-.66", 12/C-.68"	<b>OPTIONS</b>	
<b>ELECTRICAL</b>		#18 AWG (PVC) Plug Assemblies	
Voltage Rating	600 VAC	Stainless Steel Couplers	
Contact Resistance	≤5mΩ	Plastic Couplers	

## DOUBLE END CABLE ASSEMBLIES

CABLE ASSEMBLY PART NUMBERS							
Number of Poles	Male Face View	Female Face View	Wiring Color Code		AMP RTG. @ 600V	Cable Length	Male/Female Assembly
9			1-Orange 2-Blue 3-Red-Blk. Tr. 4-Green-Blk. Tr. 5-White	6-Red 7-Green 8-White-Blk. Tr. 9-Black	7A	3 FT	109G0030AP
					7A	6 FT	109G0060AP
					7A	12 FT	109G0120AP
					7A	20 FT	109G0200AP
10			1-Orange 2-Blue 3-White-Blk. Tr. 4-Red-Blk. Tr. 5-Green-Blk. Tr.	6-Org.-Blk. Tr. 7-Red 8-Green 9-Black 10-White	7A	3 FT	110G0030AP
					7A	6 FT	110G0060AP
					7A	12 FT	110G0120AP
					7A	20 FT	110G0200AP
12			1-Orange 2-Blue 3-Wht.blk. Tr. 4-Red-Blk. Tr. 5-Green-Blk. Tr. 6-Org.-Blk. Tr.	7- Blue.-Blk. Tr. 8-Blk.-Wht. Tr. 9-Green 10-Red 11-White 12-Black	5A	3 FT	112G0030AP
					5A	6 FT	112G0060AP
					5A	12 FT	112G0120AP
					5A	20 FT	112G0200AP

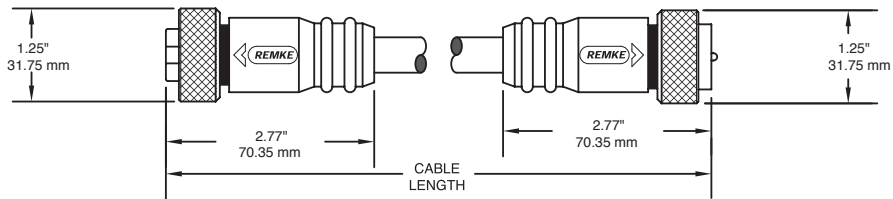

MALE/FEMALE CORDSET