



RSR SERIES ALUMINUM CORD GRIPS



RSR SERIES 90° ALUMINUM CORD GRIPS

Tuff-Seal™ 90° RSR Cord Grips are UL Listed and CSA Certified for use in both indoor and outdoor applications to prevent cable pullout, control arc of bend, and to provide a tight seal against environmental elements such as dirt, moisture and coolants.

These cord grips with external threads offer the same features as the straight RSR grips described on page 14. 90° grips can be ordered with or without wire mesh attachments, accommodate conduit sizes from 3/8" to 2" and are available in machined aluminum, nylon and Valox®.

For applications known for their severe conditions – such as oil and gas, marine, food & chemical processing – RSR 90° Cord Grips are available in nickel-plated aluminum. Providing exceptional corrosion resistance and high wear resistance, nickel-plated connectors also feature an attractive finish similar to that of polished stainless steel.

These Tuff-Seal grips protect cable from damage and pull-out and are used in conduit hubs or knock-outs at the point where the electrical cable is to be terminated.

NOTES

CORD GRIP ACCESSORIES

Locknuts: add "-L" to any part number
O-Rings: add "-R" to any part number

OPTION: NICKEL-PLATED ALUMINUM

Add 'N' to end of prefix e.g. RSR-9003 becomes RSRN-9003

OPTION: ANODIZED ALUMINUM

Add 'A' to end of prefix e.g. RSR-9003 becomes RSRA-9003

SPECIAL CONFIGURATIONS


Special configurations and materials are available. Consult factory.

All wire mesh is stainless steel.

Dimension & certification information on pages 62 & 64 in Tuff-Seal Technical Reference



COMPLETE ASSEMBLY PART NUMBERS

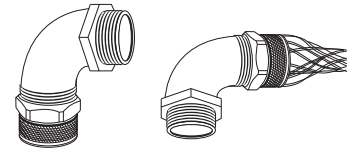


RSR SERIES ALUMINUM CORD GRIPS

Conduit Size (NPT)	Cable Range	Cord Grip	Cord Grip With Mesh
3/8"	.125 – .188	RSR-9003	***
	.188 – .250	RSR-9004	RSR-9004-E
	.250 – .312	RSR-9005	RSR-9005-E
	.312 – .375	RSR-9006	RSR-9006-E
	.375 – .438	RSR-9007	RSR-9007-E
1/2"	.125 – .188	RSR-9103	***
	.188 – .250	RSR-9104	RSR-9104-E
	.250 – .312	RSR-9105	RSR-9105-E
	.312 – .375	RSR-9106	RSR-9106-E
	.375 – .438	RSR-9107	RSR-9107-E
	.438 – .500	RSR-9108	RSR-9108-E
	.500 – .562	RSR-9109	RSR-9109-E
	.562 – .625	RSR-9110	RSR-9110-E
3/4"	.438 – .500	RSR-9208	RSR-9208-E
	.500 – .562	RSR-9209	RSR-9209-E
	.562 – .625	RSR-9210	RSR-9210-E
	.562 – .688	RSR-9211	RSR-9211-E
	.625 – .750	RSR-9212	RSR-9212-E
	.688 – .812	RSR-9213	RSR-9213-E
1"	.500 – .562	RSR-9309	RSR-9309-E
	.562 – .625	RSR-9310	RSR-9310-E
	.562 – .688	RSR-9311	RSR-9311-E
	.625 – .750	RSR-9312	RSR-9312-E
	.688 – .812	RSR-9313	RSR-9313-E
	.750 – .875	RSR-9314	RSR-9314-E
	.812 – .938	RSR-9315	RSR-9315-E
	.875 – 1.000	RSR-9316	RSR-9316-E
1 1/4"	.562 – .688	RSR-9411	***
	.688 – .812	RSR-9413	***
	.750 – .875	RSR-9414	RSR-9414-E
	.875 – 1.000	RSR-9416	RSR-9416-E
	1.000 – 1.125	RSR-9418	RSR-9418-E
	1.125 – 1.250	RSR-9420	RSR-9420-E
1 1/2"	1.250 – 1.375	RSR-9422	RSR-9422-E
	.562 – .688	RSR-9511	***
	.688 – .812	RSR-9513	***
	.750 – .875	RSR-9514	RSR-9514-E
	.875 – 1.000	RSR-9516	RSR-9516-E
	1.000 – 1.125	RSR-9518	RSR-9518-E
	1.125 – 1.250	RSR-9520	RSR-9520-E
	1.250 – 1.375	RSR-9522	RSR-9522-E
	1.438 – 1.562	RSR-9525	RSR-9525-E
	1.562 – 1.688	RSR-9527	RSR-9527-E
2"	1.688 – 1.800	RSR-9529	RSR-9529-E
	1.250 – 1.375	RSR-9622	RSR-9622-E
	1.438 – 1.562	RSR-9625	RSR-9625-E
	1.562 – 1.688	RSR-9627	RSR-9627-E
	1.688 – 1.800	RSR-9629	RSR-9629-E

*Cable may have to be stripped to pass through the bore of the body

***Contact Remke for mesh availability of this part number

COMPONENT PART NUMBERS

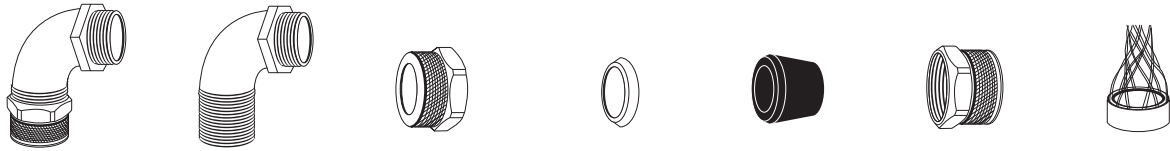

	Cord Grip Less Bushing	Body Only	Nut Only**	Washer Only	Bushing Only	Nut for Mesh Only	Mesh Only
	RSR-9000-W	RSR-9000-B	RSR-000-N	SW-000	SRB-003	***	***
	RSR-9000-W	RSR-9000-B	RSR-000-N	SW-000	SRB-004	RSR-000-ND	R-005-D
	RSR-9000-W	RSR-9000-B	RSR-000-N	SW-000	SRB-005	RSR-000-ND	R-005-D
	RSR-9000-W	RSR-9000-B	RSR-000-N	SW-000	SRB-006	RSR-000-ND	R-007-D
	RSR-9000-W	RSR-9000-B	RSR-000-N	SW-000	SRB-007	RSR-000-ND	R-007-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-103	***	***
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-104	RSR-100-ND	R-104-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-105	RSR-100-ND	R-106-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-106	RSR-100-ND	R-106-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-107	RSR-100-ND	R-108-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-108	RSR-100-ND	R-108-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-109	RSR-100-ND	R-110-D
	RSR-9100-W	RSR-9100-B	RSR-100-N	SW-100	SRB-110*	RSR-100-ND	R-110-D
	RSR-9200-W	RSR-9200-B	RSR-200-N	SW-200	SRB-208	RSR-200-ND	R-210-D
	RSR-9200-W	RSR-9200-B	RSR-200-N	SW-200	SRB-209	RSR-200-ND	R-210-D
	RSR-9200-W	RSR-9200-B	RSR-200-N	SW-200	SRB-210	RSR-200-ND	R-210-D
	RSR-9200-W	RSR-9200-B	RSR-200-N	SW-200	SRB-211	RSR-200-ND	R-212-D
	RSR-9200-W	RSR-9200-B	RSR-200-N	SW-200	SRB-212	RSR-200-ND	R-212-D
	RSR-9200-W	RSR-9200-B	RSR-200-N	SW-200	SRB-213*	RSR-200-ND	R-214-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-309	RSR-300-ND2	R-210-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-310	RSR-300-ND2	R-210-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-311	RSR-300-ND2	R-212-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-312	RSR-300-ND2	R-212-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-313	RSR-300-ND	R-314-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-314	RSR-300-ND	R-314-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-315	RSR-300-ND	R-316-D
	RSR-9300-W	RSR-9300-B	RSR-300-N	SW-300	SRB-316	RSR-300-ND	R-316-D
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-511	***	***
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-513	***	***
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-514	RSR-500-ND	R-516-D
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-516	RSR-500-ND	R-516-D
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-518	RSR-500-ND	R-518-D
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-520	RSR-500-ND	R-520-D
	RSR-9400-W	RSR-9400-B	RSR-500-N	SW-500	SRB-522*	RSR-500-ND	R-522-D
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-511	***	***
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-513	***	***
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-514	RSR-500-ND	R-516-D
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-516	RSR-500-ND	R-516-D
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-518	RSR-500-ND	R-518-D
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-520	RSR-500-ND	R-520-D
	RSR-9500-W	RSR-9500-B	RSR-500-N	SW-500	SRB-522	RSR-500-ND	R-522-D
	RSR-9601-W	RSR-9601-B	RSR-600-N	SW-600	SRB-625	RSR-600-ND	R-625-D
	RSR-9601-W	RSR-9601-B	RSR-600-N	SW-600	SRB-627	RSR-600-ND	R-627-D
	RSR-9601-W	RSR-9601-B	RSR-600-N	SW-600	SRB-629	RSR-600-ND	R-629-D
	RSR-9600-W	RSR-9600-B	RSR-600-N	SW-600	SRB-622	RSR-600-ND	R-625-D
	RSR-9600-W	RSR-9600-B	RSR-600-N	SW-600	SRB-625	RSR-600-ND	R-625-D
	RSR-9600-W	RSR-9600-B	RSR-600-N	SW-600	SRB-627	RSR-600-ND	R-627-D
	RSR-9600-W	RSR-9600-B	RSR-600-N	SW-600	SRB-629	RSR-600-ND	R-629-D

**Nuts sold as components are marked UL/CSA

***Contact Remke for mesh availability of this part number

CORD CONNECTORS

WIRE MESH GRIPS

PICO-LINK

MICRO-LINK

ETHERLINK

MINI-LINK

MULTI-PORT BOXES

BUS SYSTEM PRODUCTS

