



FS/FD™ Metallic Connections

Plug, Female Plug and Connector Dimensions

AMPS		A	B	C	E	F	G	H
10 Amp	Inches	1.75	3.62	2.25	2.00	4.00	1.87	.75
	mm	45.65	92.07	57.15	50.80	101.60	47.62	19.050
15 Amp	Inches	1.75	3.62	2.25	2.00	4.00	1.87	.75
	mm	45.65	92.07	57.15	50.80	101.60	47.62	19.050
20 Amp	Inches	1.75	3.62	2.25	2.00	4.00	1.87	.75
	mm	45.65	92.07	57.15	50.80	101.60	47.62	19.050
30 Amp	Inches	1.87	3.75	2.25	2.25	4.25	2.25	1.12
	mm	47.62	95.25	57.15	57.15	107.95	57.15	28.57

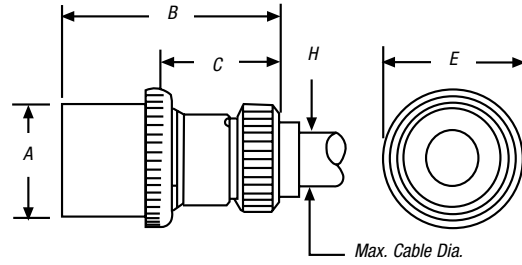


Plugs and Female Plugs

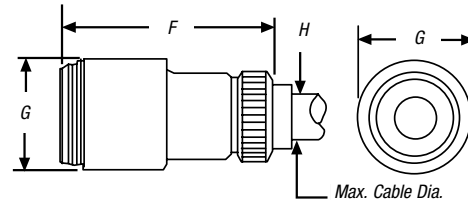


Connectors

Receptacles and Male Receptacles

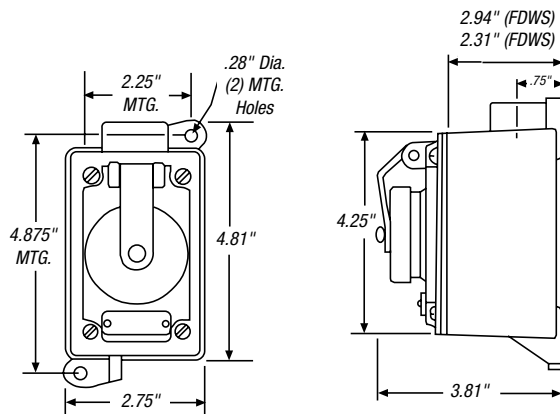

Standard Die-Cast Aluminum Back Box
(FSWS/FDWS)

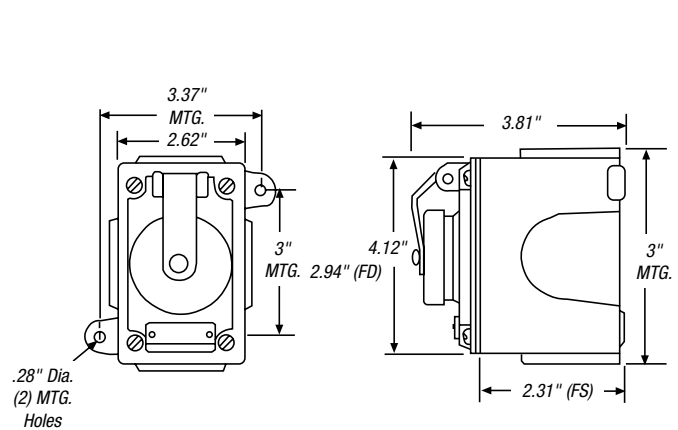

Cast Aluminum/Cast Brass Back Box
(3701-3732 Series)