



# STI External Lighting & CCTV Cages

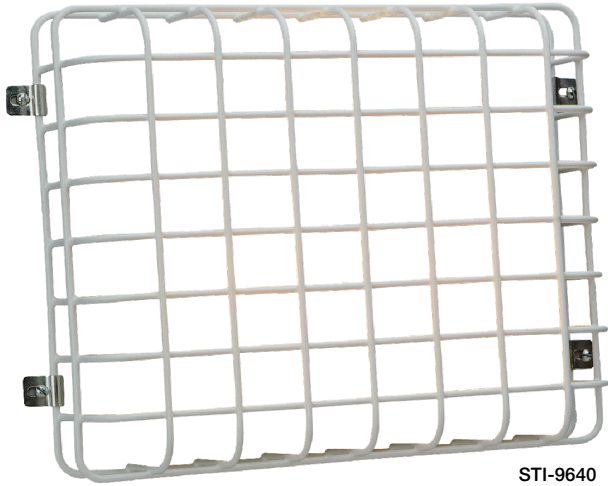

STI-9640

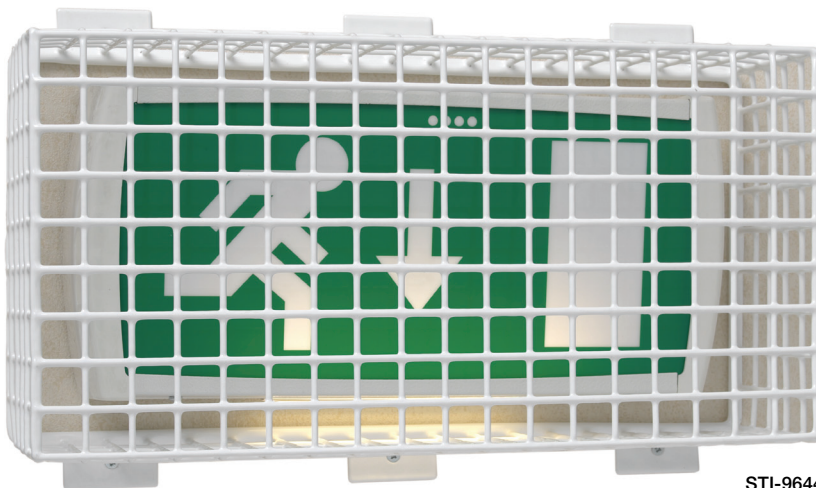

STI-9644

## PRODUCT OVERVIEW

These steel cages are designed to protect a variety of equipment including CCTV cameras and external lighting from vandalism and misuse. They are easy to install with full fixing kit provided. Constructed from plastic coated, heavy-duty galvanised steel rod, they can cope with the severest of abuse from vandalism and accidental damage.

## HOW IT WORKS

A simple 4 fixing point installation makes them easy to mount, and removal is simple for servicing the protected device. They are highly recommended for areas where abuse is severe or it is imperative external lighting and CCTV cameras continue to operate.

## KEY FEATURES

### General Information

- Help to protect external lighting and CCTV cameras from theft and vandalism.
- Three year guarantee against breakage in normal use.

### Design

- These steel cages are designed to protect a variety of equipment including CCTV and external lighting from vandalism and misuse.
- Designed so there is no interference with the operation of the protected device.

### Construction

- Constructed from plastic coated, heavy-duty galvanised steel rod.

### Installation

- A simple 4 fixing point installation can retrofit over existing devices.
- Fast and easy installation.
- Simple removal for servicing of devices.

### Options

- Where additional security is required, tamper resistant screws and matching bits are available.



# STI External Lighting & CCTV Cages


Dimensions and Technical Information

## MODELS AVAILABLE

- STI-9625** External Lighting Cage
- STI-9626** External Lighting Cage
- STI-9627** External Lighting Cage
- STI-9644** External Lighting Cage
- STI-9646** External Lighting & CCTV Cage - Medium
- STI-9647** External Lighting & CCTV Cage - Large
- STI-9729** External Lighting & CCTV Cage - Medium
- STI-9730** External Lighting & CCTV Cage - Large

\*NB Cage sizes may vary from -5 to +5 millimetres

Product Code	Height	Width	Depth
<b>STI-9625</b>	200mm	260mm	321mm
<b>STI-9626</b>	530mm	450mm	300mm
<b>STI-9627</b>	400mm	400mm	400mm
<b>STI-9644</b>	220mm	450mm	133mm
<b>STI-9646</b>	498mm	498mm	514mm
<b>STI-9647</b>	620mm	620mm	640mm
<b>STI-9729</b>	178mm	178mm	178mm
<b>STI-9730</b>	315mm	315mm	309mm

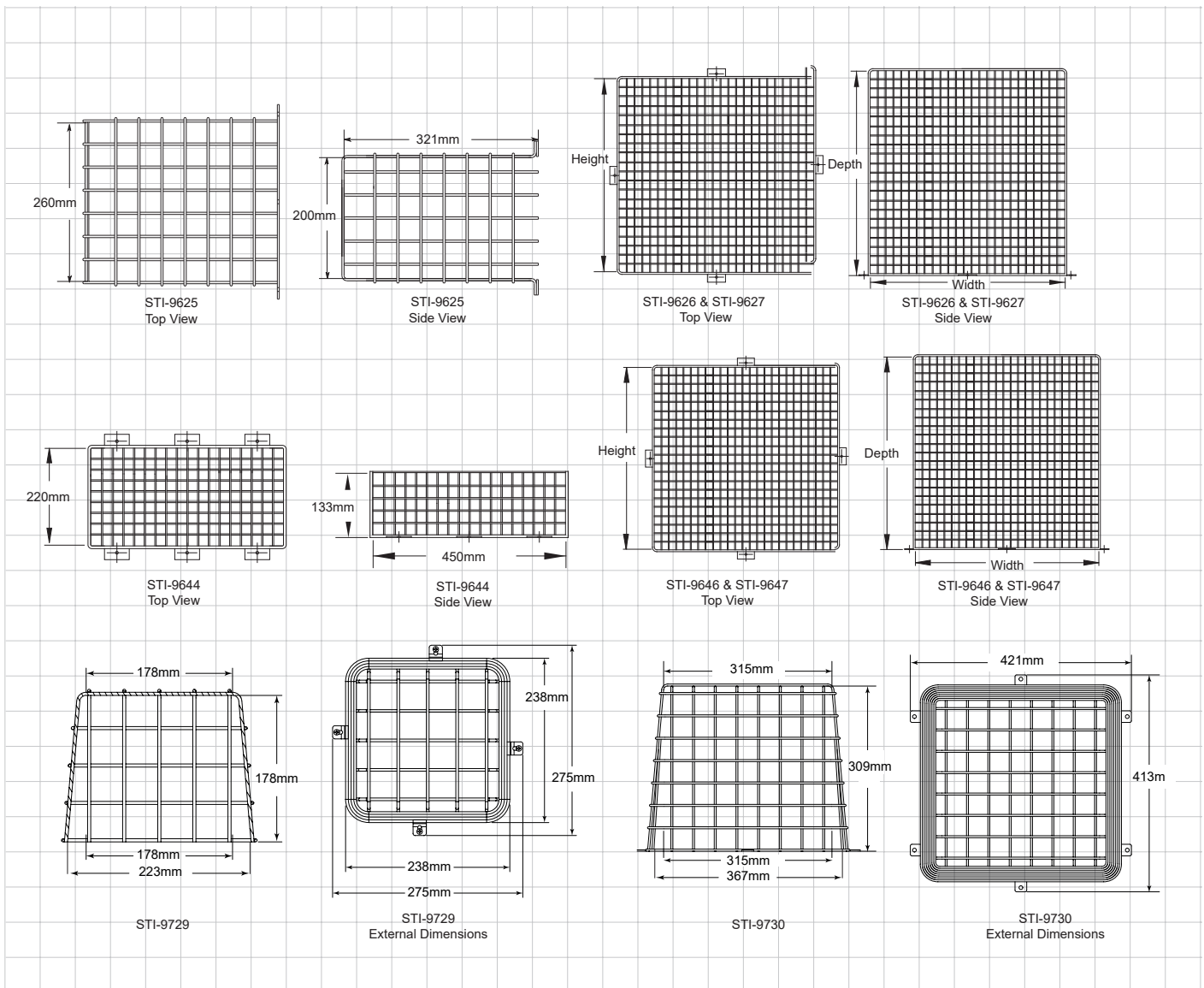

**Safety Technology International**