

ENVIROLINE® SERIES TWO-DOOR ENCLOSURES WITH 3-POINT HARDWARE

Application

Designed to house electrical and electronic controls, instrumentation and components in indoor & outdoor locations. For outdoor applications a drip shield is recommended. For installation information, consult our installation manual at www.saginawcontrol.com.

Construction

- 0.104" carbon steel.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Removable center post.
- Heavy duty lifting eyes anchored into reinforced top.
- Body stiffeners.
- Concealed hinges.
- Black keylocking/padlocking handles.
- 3-point latching mechanism.
- Removable print pocket.
- 12" removable floor stands.
- Panel supports.
- Black quarter turn latches as required.
- Provisions for mechanical interlock.
- Pour in place oil & water resistant gasket.
- Ground stud on door and body.
- Provisions for light kit.
- Hole plugs provided to seal holes in bottom of enclosure.

Options

Provisions for mechanical interlock. See Accessory section to order.

Finish

ANSI-61 gray powder coated inside and out. Optional subpanels powder coated white.

IS4 Industry Standards

NEMA Type 3R, 4, 12 & Type 13
UL Listed Type 3R, 4 & 12
CSA Type 3R, 4 & 12
IEC 60529 IP66

***To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs. Drip shield over the door is recommended for all outdoor applications.


Enclosure Product Code E2

Subpanel (P3)

Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	Catalog No.	Panel Height (D)	Panel Width (E)
SCE-60EL4812LPPL	60.00	48.00	12.00	IS4	SCE-60P48	56.00	44.00
SCE-60EL4818LPPL	60.00	48.00	18.00	IS4	SCE-60P48	56.00	44.00
SCE-60EL6012LPPL	60.00	60.00	12.00	IS4	SCE-60P60	56.00	56.00
SCE-60EL6018LPPL	60.00	60.00	18.00	IS4	SCE-60P60	56.00	56.00
SCE-72EL6012LPPL	72.00	60.00	12.00	IS4	SCE-72P60	68.00	56.00
SCE-72EL6018LPPL	72.00	60.00	18.00	IS4	SCE-72P60	68.00	56.00
SCE-72EL7212LPPL	72.00	72.00	12.00	IS4	SCE-72P72	68.00	68.00
SCE-72EL7218LPPL	72.00	72.00	18.00	IS4	SCE-72P72	68.00	68.00
SCE-72EL7224LPPL	72.00	72.00	24.00	IS4	SCE-72P72	68.00	68.00



ENVIROLINE® SERIES TWO-DOOR ENCLOSURES WITH 3-POINT HARDWARE TECHNICAL DATA

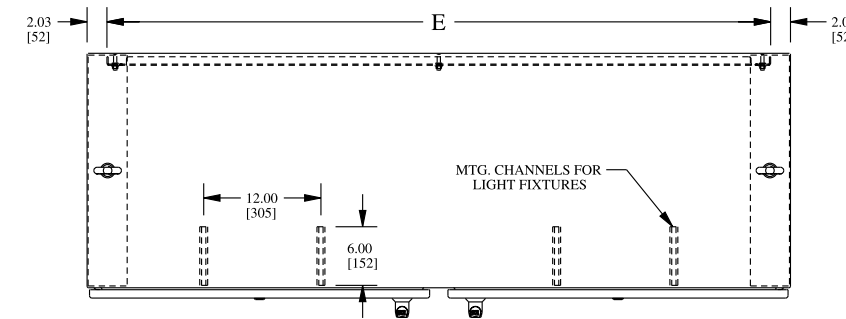

LATCH NOTE:
Omit center latch top and bottom of door when door width is < 30.00 [762]

