

# STAINLESS STEEL DESK CONSOLES

## 304 STAINLESS STEEL DESK CONSOLES

| Enclosure Product Code S10                      |            |           |           | Subpanel (P3)     |                            |                  |                 |
|-------------------------------------------------|------------|-----------|-----------|-------------------|----------------------------|------------------|-----------------|
| Catalog no.                                     | Height (A) | Width (B) | Depth (C) | Industry Standard | Catalog No.                | Panel Height (D) | Panel Width (E) |
| <b>Single Access Single-Door</b>                |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-402516SDCSS</a>                 | 40.25      | 25.25     | 15.5      | IS6               | <a href="#">SCE-30P24</a>  | 27.00            | 21.00           |
| <a href="#">SCE-403716SDCSS</a>                 | 40.25      | 37.25     | 15.5      | IS6               | <a href="#">SCE-36P30</a>  | 33.00            | 27.00           |
| <a href="#">SCE-462519SDCSS</a>                 | 46.25      | 25.25     | 18.5      | IS6               | <a href="#">SCE-36P24</a>  | 33.00            | 21.00           |
| <a href="#">SCE-463719SDCSS</a>                 | 46.25      | 37.25     | 18.5      | IS3               | <a href="#">SCE-36P36</a>  | 33.00            | 33.00           |
| <b>Dual Access Single-Door</b>                  |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-462519DCSS</a>                  | 46.25      | 25.25     | 18.5      | IS6               | <a href="#">SCE-36P24</a>  | 33.00            | 21.00           |
| <a href="#">SCE-463719DCSS</a>                  | 46.25      | 37.25     | 18.5      | IS3               | <a href="#">SCE-36P36</a>  | 33.00            | 33.00           |
| <b>Single Access Overlapping Two-Door</b>       |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-464919SDCSS</a>                 | 46.25      | 49.25     | 18.5      | IS3               | <a href="#">SCE-48P36</a>  | 45.00            | 33.00           |
| <a href="#">SCE-466019SDCSS</a>                 | 46.25      | 59.88     | 18.5      | IS3               | <a href="#">SCE-60PC36</a> | 55.63            | 33.00           |
| <b>Dual Access Overlapping Two-Door</b>         |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-464919DCSS</a>                  | 46.25      | 49.25     | 18.5      | IS3               | <a href="#">SCE-48P36</a>  | 45.00            | 33.00           |
| <a href="#">SCE-466019DCSS</a>                  | 46.25      | 59.88     | 18.5      | IS3               | <a href="#">SCE-60PC36</a> | 55.63            | 33.00           |
| <b>Dual Access Two-Door With Center Channel</b> |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-464919DCCSS</a>                 | 46.25      | 49.25     | 18.5      | IS6               | <a href="#">SCE-48P36</a>  | 45.00            | 33.00           |
| <a href="#">SCE-466019DCCSS</a>                 | 46.25      | 59.88     | 18.5      | IS6               | <a href="#">SCE-60PC36</a> | 55.63            | 33.00           |

## 316 STAINLESS STEEL DESK CONSOLES

| Enclosure Product Code S7                       |            |           |           | Subpanel (P3)     |                            |                  |                 |
|-------------------------------------------------|------------|-----------|-----------|-------------------|----------------------------|------------------|-----------------|
| Catalog no.                                     | Height (A) | Width (B) | Depth (C) | Industry Standard | Catalog No.                | Panel Height (D) | Panel Width (E) |
| <b>Single Access Single-Door</b>                |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-402516SDCSS6</a>                | 40.25      | 25.25     | 15.50     | IS6               | <a href="#">SCE-30P24</a>  | 27.00            | 21.00           |
| <a href="#">SCE-403716SDCSS6</a>                | 40.25      | 37.25     | 15.50     | IS3               | <a href="#">SCE-36P30</a>  | 33.00            | 27.00           |
| <a href="#">SCE-462519SDCSS6</a>                | 46.25      | 25.25     | 18.50     | IS6               | <a href="#">SCE-36P24</a>  | 33.00            | 21.00           |
| <a href="#">SCE-463719SDCSS6</a>                | 46.25      | 37.25     | 18.50     | IS3               | <a href="#">SCE-36P36</a>  | 33.00            | 33.00           |
| <b>Dual Access Single-Door</b>                  |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-462519DCSS6</a>                 | 46.25      | 25.25     | 18.50     | IS6               | <a href="#">SCE-36P24</a>  | 33.00            | 21.00           |
| <a href="#">SCE-463719DCSS6</a>                 | 46.25      | 37.25     | 18.00     | IS3               | <a href="#">SCE-36P36</a>  | 33.00            | 33.00           |
| <b>Single Access Overlapping Two-Door</b>       |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-464919SDCSS6</a>                | 46.25      | 49.25     | 18.50     | IS3               | <a href="#">SCE-48P36</a>  | 45.00            | 33.00           |
| <a href="#">SCE-466019SDCSS6</a>                | 46.25      | 59.88     | 18.50     | IS3               | <a href="#">SCE-60PC36</a> | 55.63            | 33.00           |
| <b>Dual Access Overlapping Two-Door</b>         |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-464919DCSS6</a>                 | 46.25      | 49.25     | 18.50     | IS3               | <a href="#">SCE-48P36</a>  | 45.00            | 33.00           |
| <a href="#">SCE-466019DCSS6</a>                 | 46.25      | 59.88     | 18.50     | IS3               | <a href="#">SCE-60PC36</a> | 55.63            | 33.00           |
| <b>Dual Access Two-Door With Center Channel</b> |            |           |           |                   |                            |                  |                 |
| <a href="#">SCE-464919DCCSS6</a>                | 46.25      | 49.25     | 18.50     | IS6               | <a href="#">SCE-48P36</a>  | 45.00            | 33.00           |
| <a href="#">SCE-466019DCCSS6</a>                | 46.25      | 59.88     | 18.50     | IS6               | <a href="#">SCE-60PC36</a> | 55.63            | 33.00           |



### Application

Intended for indoor use to provide a degree of protection to personnel against access to hazardous parts, also to provide a degree of protection for the equipment inside the enclosure against ingress of solid foreign objects and falling dirt, to provide a degree of protection with respect to harmful effects on the equipment due to the ingress of water, splashing water. Designed for use in standing or sitting position with single and dual access and top that opens for easy accessibility. For installation information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com).

### Construction

- 0.075" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- 25 Degree Sloped top.
- Door props on sloped door to hold in the open position.
- Oil and water resistant gasket.
- Flange trough collar around all sides of door opening.
- Concealed hinges.
- Removable doors.
- Removable print pocket.
- Ground studs on door and body.
- Rubber pads with provision for leveling pads on bottom of enclosure.
- Black quarter turn latches on top door.
- Padlocking and keylocking black 3-point flush swing handle in front door of single access, front and rear doors on dual access.
- Mounting studs welded on interior back for mounting optional subpanels on single access console.
- Mounting channels welded on sides of interior body for mounting optional subpanels on dual access console.
- Mounting hardware included for (1) optional subpanel.

### Options

Can be special ordered in Type 316/316L stainless steel.

### Finish

#4 brushed finish on all exterior surfaces. Optional subpanels powder coated white.

### IS3 Industry Standards

NEMA Type 3R, 12 & Type 13  
UL Listed Type 3R & 12  
CSA Type 3R & 12  
IEC 60529 IP55

### IS6 Industry Standards


NEMA Type 3R, 4, 4X, 12 & Type 13  
UL Listed Type 3R, 4, 4X & 12  
CSA Type 3R, 4, 4X & 12  
IEC 60529 IP66

\*\*\*To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs. Drip shield over the door is recommended for all outdoor applications.

# STAINLESS STEEL DESK CONSOLES

## TECHNICAL DATA

### SINGLE ACCESS SINGLE-DOOR

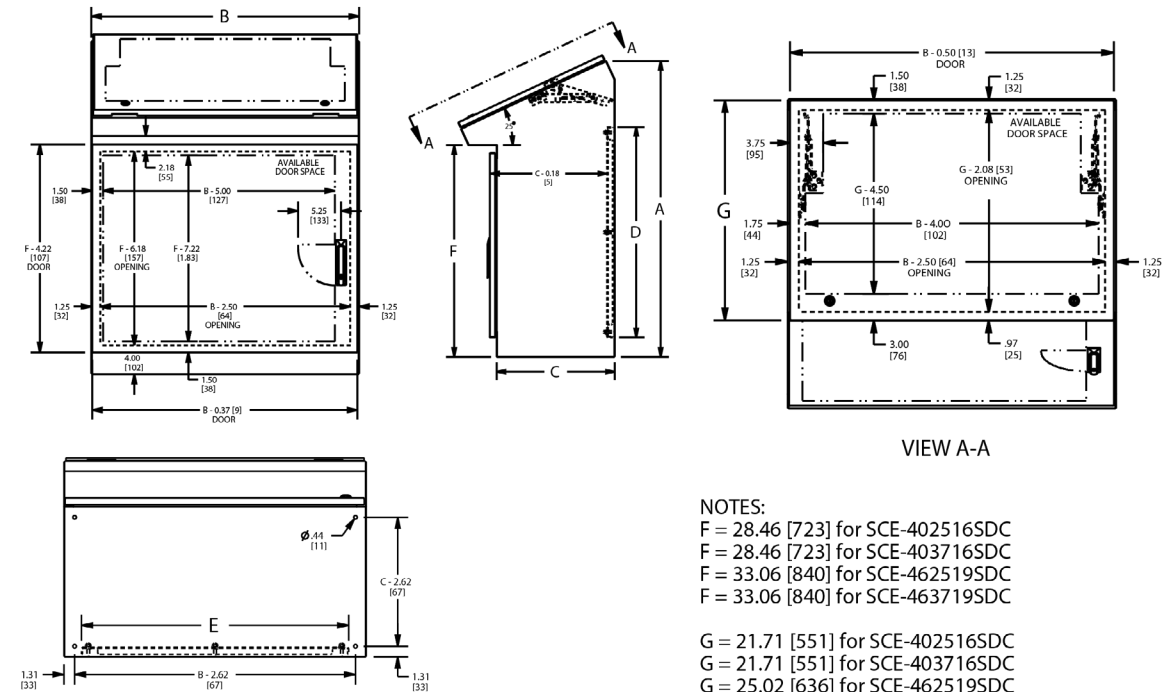


VIEW A-A

#### NOTES:

F = 28.46 [723] for SCE-402516SDC  
F = 28.46 [723] for SCE-403716SDC  
F = 33.06 [840] for SCE-462519SDC  
F = 33.06 [840] for SCE-463719SDC

G = 21.71 [551] for SCE-402516SDC  
G = 21.71 [551] for SCE-403716SDC  
G = 25.02 [636] for SCE-462519SDC  
G = 25.02 [636] for SCE-463719SDC

### DUAL ACCESS SINGLE-DOOR

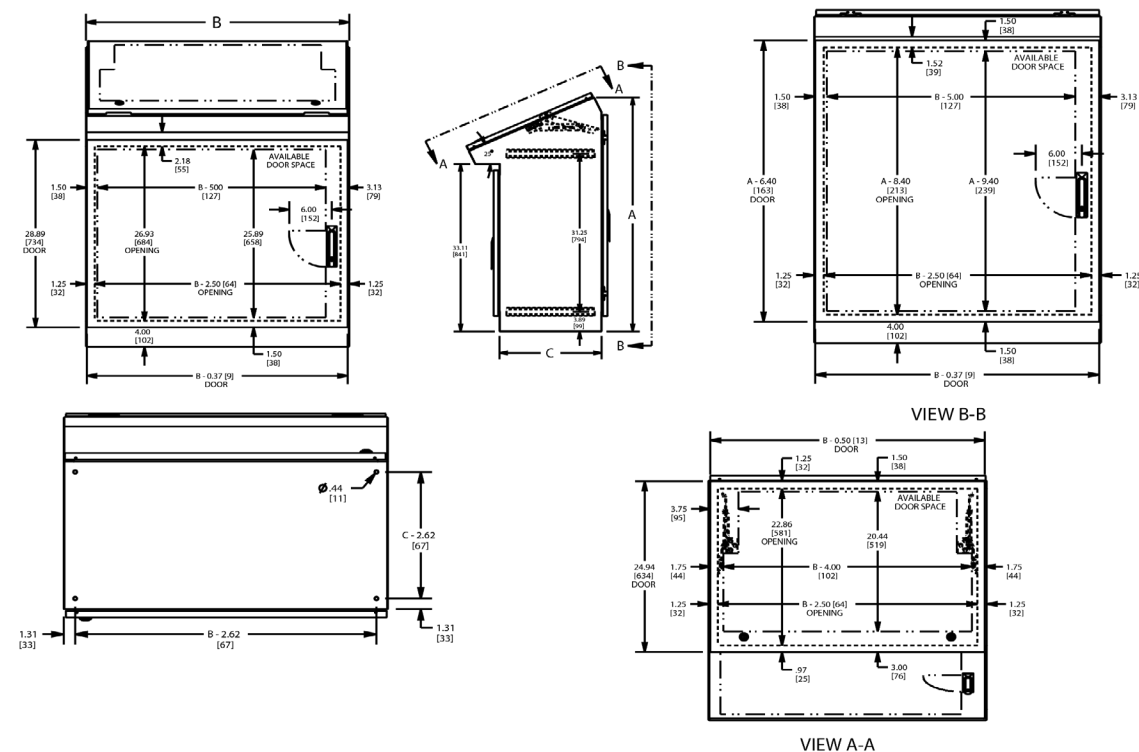

VIEW B-B

VIEW A-A