

## Application

Designed for electronic controls and instruments. Equipment can be mounted on the sloping control panel door. Interior components mount to stationary panels. Provides protection from dirt, oil, dust and water. For installation information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com)

## Construction

- 0.104" carbon steel.
- Sloping control panel door attached with concealed hinge on bottom edge. Door opens to 90 degree.
- Black zinc die cast keylocking/padlocking handles on front and rear doors.
- 3-point latching mechanism.
- Seams continuously welded and ground smooth.
- Pour in place oil and water resistant gasket on door.
- Optional equipment mounts to horizontal channels welded to sides.
- Optional writing desk and top section available.
- Interior print pocket.
- Removable eyebolts in console body.
- Ground stud on door and body.
- Hole plugs provided to seal holes in bottom of enclosure.

## Finish

ANSI-61 gray powder coated inside and out. Optional panels are powder coated white.

## IS3 Industry Standards

NEMA Type 3R, 12 & Type 13  
UL Listed Type 3R & 12  
CSA Type 3R & 12  
IEC 60529 IP55

\*\*\*To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs.




## SERIES 14 SINGLE-DOOR CONSOLES - 24" WIDE

Catalog No.	Description	Enclosures				
		Height (A)	Width (B)	Depth (C)	Product Code	Industry Standard
<a href="#">SCE-14B</a>	Console Body	50.00	24.00	23.00	C1	IS3
<a href="#">SCE-14T</a>	Console Top	16.00	24.00	12.50	C1	IS1
<a href="#">SCE-14P1</a>	Swing-Out Panel	22.00	18.12		P2	IS1
<a href="#">SCE-14P2</a>	Half Panel	22.00	17.00		P3	IS1
<a href="#">SCE-14P3</a>	Full Panel	42.25	17.00		P3	IS1
<a href="#">SCE-14R</a>	Rack Angles	29.00	(set of 2)		P2	IS1
<a href="#">SCE-14W</a>	Writing Desk	24.00	10.00		P2	IS1

## SERIES 14 SINGLE-DOOR CONSOLES - 36" WIDE

Catalog No.	Description	Enclosures				
		Height (A)	Width (B)	Depth (C)	Product Code	Industry Standard
<a href="#">SCE-1436B</a>	Console Body	50.00	36.00	23.00	C1	IS3
<a href="#">SCE-1436T</a>	Console Top	16.00	36.00	12.50	C1	IS1
<a href="#">SCE-1436P1</a>	Swing-Out Panel	22.00	30.12		P2	IS1
<a href="#">SCE-1436P2</a>	Half Panel	22.00	29.00		P3	IS1
<a href="#">SCE-1436P3</a>	Full Panel	42.25	29.00		P3	IS1
<a href="#">SCE-1436W</a>	Writing Desk	36.00	10.00		P2	IS1

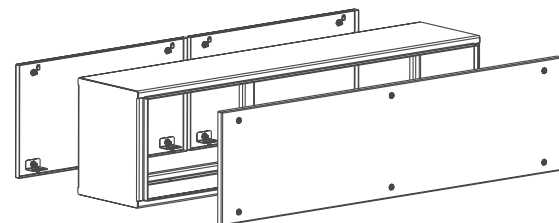

### OPTIONAL TOP NOTES:

1. SINGLE FRONT & SINGLE REAR ACCESS PANEL ON ENCLOSURES < 48.00 [1219] WIDE.
2. SINGLE FRONT & TWO REAR ACCESS PANELS ON 48.00 [1219] & 60.00 [1524] WIDE
3. TWO FRONT & TWO REAR ACCESS PANELS ON 72.00 [1829] WIDE.

