

**Application**

Designed to house standard pushbuttons, switches and pilot lights in wet and hosed down areas and in corrosive atmospheres. For installation information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com).

**Construction**

- 0.063" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- Captivated cover screws thread into sealed wells.
- Four-way pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights. Hole diameter 0.87" (22.5 mm).
- Immediate removal of cover is permitted.
- Pour in place oil and water resistant gasket.
- Welded mounting provision top and bottom of back.

**Finish**

#4 brushed finish on all exterior surfaces

**IS5 Industry Standards**

NEMA Type 4, 4X, 12 & Type 13  
UL Listed Type 4, 4X & 12  
CSA Type 4, 4X & 12  
IEC 60529 IP66






**304 STAINLESS STEEL**

Enclosure Product Code S1				
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard
<a href="#">SCE-1PBSSI</a>	3.50	3.25	2.75	IS5
<a href="#">SCE-1PBXSSI</a>	4.00	4.00	4.75	IS5
<a href="#">SCE-2PBSSI</a>	5.75	3.25	2.75	IS5
<a href="#">SCE-3PBSSI</a>	8.00	3.25	2.75	IS5
<a href="#">SCE-4PBSSI</a>	10.25	3.25	2.75	IS5
<a href="#">SCE-4PBXSSI</a>	10.00	4.00	4.75	IS5
<a href="#">SCE-4SPBSSI</a>	7.25	6.25	3.00	IS5
<a href="#">SCE-6PBSSI</a>	9.50	6.25	3.00	IS5
<a href="#">SCE-9PBSSI</a>	9.50	8.50	3.00	IS5
<a href="#">SCE-12PBSSI</a>	11.75	8.50	3.00	IS5

**316 STAINLESS STEEL**

Enclosure Product Code S1				
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard
<a href="#">SCE-1PBSS6I</a>	3.50	3.25	2.75	IS5
<a href="#">SCE-1PBXSS6I</a>	4.00	4.00	4.75	IS5
<a href="#">SCE-2PBSS6I</a>	5.75	3.25	2.75	IS5
<a href="#">SCE-3PBSS6I</a>	8.00	3.25	2.75	IS5
<a href="#">SCE-4PBSS6I</a>	10.25	3.25	2.75	IS5
<a href="#">SCE-4PBXSS6I</a>	10.00	4.00	4.75	IS5
<a href="#">SCE-4SPBSS6I</a>	7.25	6.25	3.00	IS5
<a href="#">SCE-6PBSS6I</a>	9.50	6.25	3.00	IS5
<a href="#">SCE-9PBSS6I</a>	9.50	8.50	3.00	IS5
<a href="#">SCE-12PBSS6I</a>	11.75	8.50	3.00	IS5

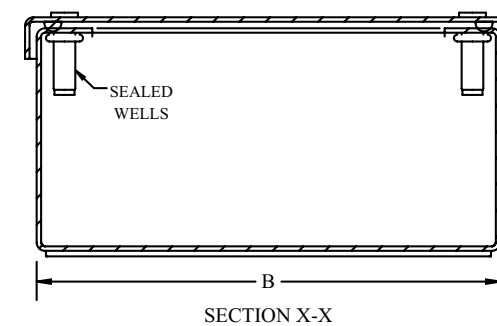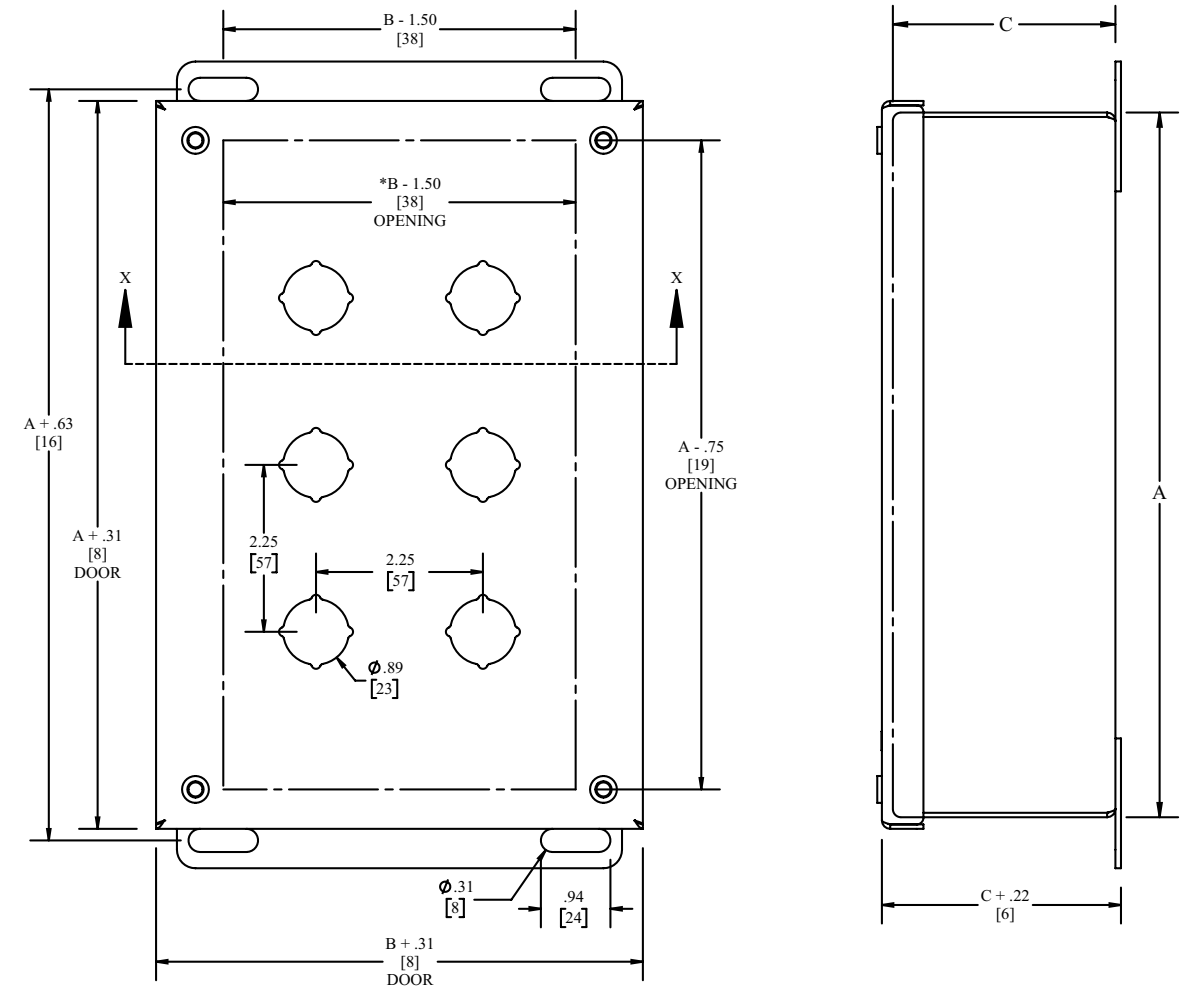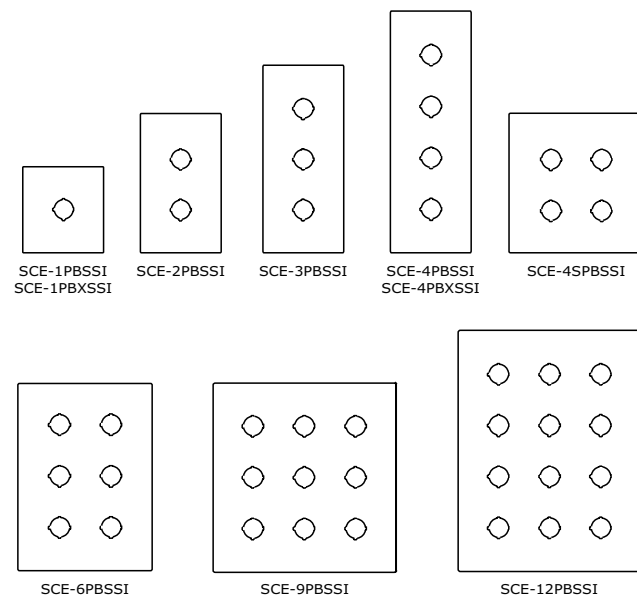

NOTE:  
\*B - .50 [13] WHEN ONE COLUMN OF PUSHBUTTONS