

# STAINLESS STEEL ENVIROLINE® SERIES WALL-MOUNT TWO-DOOR ENCLOSURES WITH 3-POINT HARDWARE

## Application

Designed to house electrical and electronic controls, instrumentation and components. For outdoor applications a drip shield is recommended. For installation information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com).

## Construction

- 0.075" stainless steel Type 304.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Collar studs provided for mounting optional subpanels.
- Removable center posts permit easy subpanel installation.
- Mounting holes in back of the enclosure for wall-mounting.
- Mounting hardware, sealing washers and hole plugs included.
- Stainless steel concealed hinges.
- Removable and interchangeable doors.
- Black keylocking padlocking handles.
- 3-point latching mechanism.
- Removable print pocket.
- Pour in place oil & water resistant gasket.
- Ground stud on door and body.

## Finish

#4 brushed finish on all exterior surfaces. Optional subpanels powder coated white.

## Options

Provisions for mechanical interlock. See accessory section to order.

## Notes

Mechanical interlock not for use in enclosures 24" in height.

## IS6 Industry Standards



NEMA Type 3R, 4, 4X, 12 & Type 13  
UL Listed Type 3R, 4, 4X & 12  
CSA Type 3R, 4, 4X & 12  
IEC 60529 IP66

\*\*\*To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs. Drip shield over the door is recommended for all outdoor applications.

Catalog No.	Enclosure Product Code S5				Subpanel (P3)		
	Height (A)	Width (B)	Depth (C)	Industry Standard	Catalog No.	Panel Height (D)	Panel Width (E)
<a href="#">SCE-24EL4210SSWFLP</a>	24.00	42.00	10.00	IS6	<a href="#">SCE-42P24</a>	39.00	21.00
<a href="#">SCE-24EL4810SSWFLP</a>	24.00	48.00	10.00	IS6	<a href="#">SCE-48P24</a>	45.00	21.00
<a href="#">SCE-30EL4210SSWFLP</a>	30.00	42.00	10.00	IS6	<a href="#">SCE-42P30</a>	39.00	27.00
<a href="#">SCE-30EL4810SSWFLP</a>	30.00	48.00	10.00	IS6	<a href="#">SCE-48P30</a>	45.00	27.00
<a href="#">SCE-30EL6010SSWFLP</a>	30.00	60.00	10.00	IS6	<a href="#">SCE-60P30</a>	57.00	27.00
<a href="#">SCE-36EL4212SSWFLP</a>	36.00	42.00	12.00	IS6	<a href="#">SCE-42P36</a>	39.00	33.00
<a href="#">SCE-36EL4812SSWFLP</a>	36.00	48.00	12.00	IS6	<a href="#">SCE-48P36</a>	45.00	33.00
<a href="#">SCE-36EL6012SSWFLP</a>	36.00	60.00	12.00	IS6	<a href="#">SCE-60P36</a>	57.00	33.00
<a href="#">SCE-42EL4212SSWFLP</a>	42.00	42.00	12.00	IS6	<a href="#">SCE-42P42</a>	39.00	39.00
<a href="#">SCE-42EL4812SSWFLP</a>	42.00	48.00	12.00	IS6	<a href="#">SCE-48P42</a>	45.00	39.00
<a href="#">SCE-42EL6012SSWFLP</a>	42.00	60.00	12.00	IS6	<a href="#">SCE-60P42</a>	56.00	38.00
<a href="#">SCE-48EL4812SSWFLP</a>	48.00	48.00	12.00	IS6	<a href="#">SCE-48P48</a>	44.00	44.00



# STAINLESS STEEL ENVIROLINE® SERIES WALL-MOUNT TWO-DOOR ENCLOSURES WITH 3-POINT HARDWARE TECHNICAL DATA

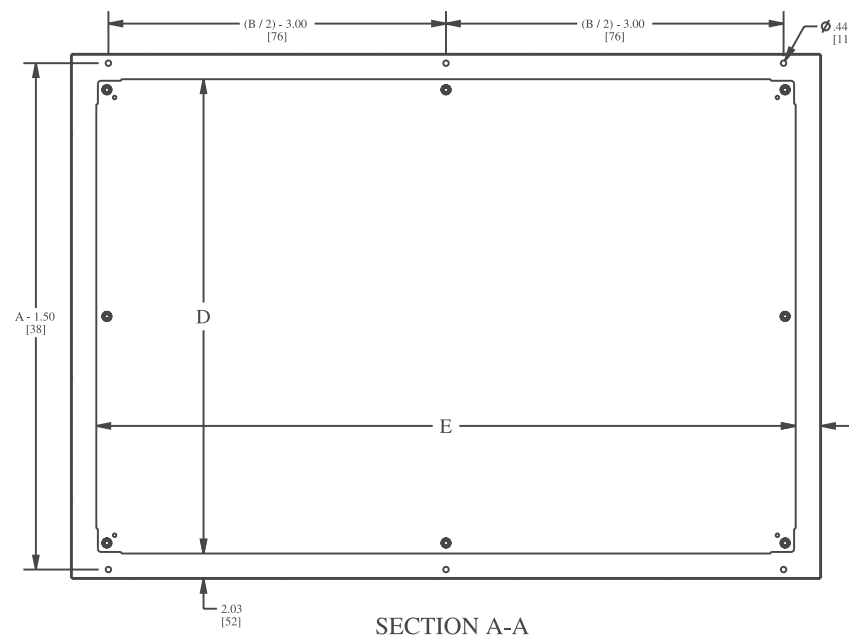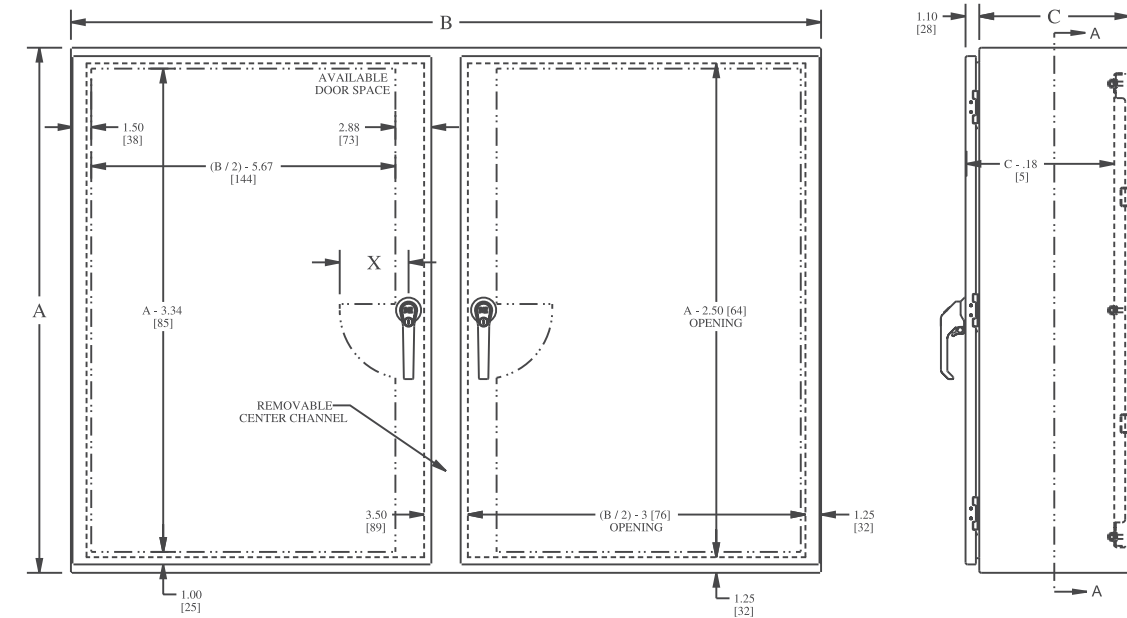

**HANDLE NOTES:**  
Enclosures ≤ 42.00 [1067] in height  
X = 5.50 [140] and uses 5.00 [127] key-locking/padlocking handle.  
Enclosures > 42.00 [1067] in height  
X = 6.75 [171] and uses 7.00 [178] key-locking/padlocking handle.