

Application

Designed to house electrical and electronic controls, instrumentation and components in indoor & outdoor locations. For outdoor applications a drip shield is recommended. For installation information, consult our installation manual at www.saginawcontrol.com.

Construction

- 0.104" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Removable center post.
- Heavy duty lifting eyes anchored into reinforced top.
- Body stiffeners.
- Black quarter turn latches as required.
- Stainless steel concealed hinges.
- Black keylocking/padlocking handles.
- 3-point latching mechanism.
- Removable print pocket.
- 12" removable floor stands.
- Panel supports.
- Provisions for mechanical interlock.
- Pour in place oil & water resistant gasket.
- Ground stud on door and body.
- Provisions for light kit.

Finish

#4 brushed finish on all exterior surfaces. Optional subpanels powder coated white.

Options

Provisions for mechanical interlock. See accessory section to order.

IS6 Industry Standards

NEMA Type 3R, 4, 4X, 12 & Type 13
UL Listed Type 3R, 4, 4X & 12
CSA Type 3R, 4, 4X & 12
IEC 60529 IP66


***To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs. Drip shield over the door is recommended for all outdoor applications.

304 STAINLESS STEEL

Enclosure Product Code S4				Subpanel (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	Catalog No.	Panel Height (D)	Panel Width (E)
SCE-60EL4812SSLPPL	60.00	48.00	12.00	IS6	SCE-60P48	56.00	44.00
SCE-60EL4818SSLPPL	60.00	48.00	18.00	IS6	SCE-60P48	56.00	44.00
SCE-60EL6012SSLPPL	60.00	60.00	12.00	IS6	SCE-60P60	56.00	56.00
SCE-60EL6018SSLPPL	60.00	60.00	18.00	IS6	SCE-60P60	56.00	56.00
SCE-72EL6012SSLPPL	72.00	60.00	12.00	IS6	SCE-72P60	68.00	56.00
SCE-72EL6018SSLPPL	72.00	60.00	18.00	IS6	SCE-72P60	68.00	56.00
SCE-72EL7212SSLPPL	72.00	72.00	12.00	IS6	SCE-72P72	68.00	68.00
SCE-72EL7218SSLPPL	72.00	72.00	18.00	IS6	SCE-72P72	68.00	68.00
SCE-72EL7224SSLPPL	72.00	72.00	24.00	IS6	SCE-72P72	68.00	68.00

316 STAINLESS STEEL

Enclosure Product Code S4				Subpanel (P3)			
Catalog No.	Height (A)	Width (B)	Depth (C)	Industry Standard	Catalog No.	Panel Height (D)	Panel Width (E)
SCE-60EL4812SS6LPPL	60.00	48.00	12.00	IS6	SCE-60P48	56.00	44.00
SCE-60EL4818SS6LPPL	60.00	48.00	18.00	IS6	SCE-60P48	56.00	44.00
SCE-60EL6012SS6LPPL	60.00	60.00	12.00	IS6	SCE-60P60	56.00	56.00
SCE-60EL6018SS6LPPL	60.00	60.00	18.00	IS6	SCE-60P60	56.00	56.00
SCE-72EL6012SS6LPPL	72.00	60.00	12.00	IS6	SCE-72P60	68.00	56.00
SCE-72EL6018SS6LPPL	72.00	60.00	18.00	IS6	SCE-72P60	68.00	56.00
SCE-72EL7212SS6LPPL	72.00	72.00	12.00	IS6	SCE-72P72	68.00	68.00
SCE-72EL7218SS6LPPL	72.00	72.00	18.00	IS6	SCE-72P72	68.00	68.00
SCE-72EL7224SS6LPPL	72.00	72.00	24.00	IS6	SCE-72P72	68.00	68.00

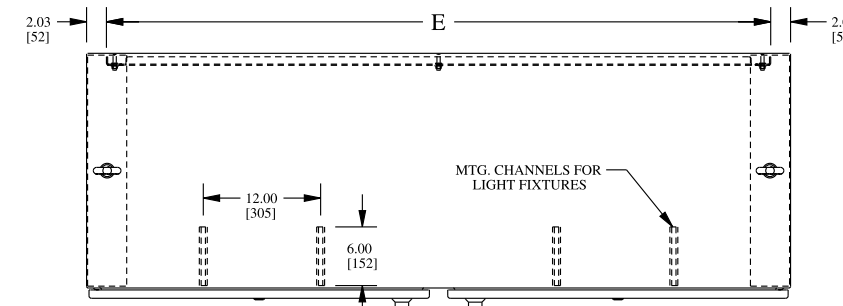

LATCH NOTE:
Omit center latch top and bottom of door when door width is < 30.00 [762]

