

Application

Designed to house electrical and electronic controls, instruments and components. Provides a degree of protection from dust, oil and water. For installation information, consult our installation manual at www.saginawcontrol.com. For outdoor applications a drip shield is recommended.

Construction

- 0.104" stainless steel Type 304 & 316/316L.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Stainless steel concealed hinges.
- Black zinc die cast keylocking/padlocking handle.
- Removable and interchangeable doors.
- Black quarter turn latches as required.
- Removable print pocket.
- Lifting eyes for easy handling.
- Ground studs on door and body.
- Mounting channels welded horizontally on sides of interior body at top, bottom and middle for mounting optional panels or rack mounting angles.
- No door stiffeners required.
- Provisions for light kit.
- Pour in place oil and water resistant gasket.

Finish

#4 brushed finish on all exterior surfaces. Optional subpanels powder coated white.

Accessories - See page 144-151

IS6 Industry Standards

NEMA Type 3R, 4, 4X, 12 & Type 13
UL Listed Type 3R, 4, 4X & 12
CSA Type 3R, 4, 4X & 12
IEC 60529 IP66

***To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs. Drip shield over the door is recommended for all outdoor applications.

304 STAINLESS STEEL


Enclosure Product Code S4

| Catalog No. | Height (A) | Width (B) | Depth (C) | Industry Standard |
|---------------------------------|------------|-----------|-----------|-------------------|
| SCE-60EL2418SSF | 60.00 | 24.00 | 18.00 | IS6 |
| SCE-60EL3624SSF | 60.00 | 36.00 | 24.00 | IS6 |
| SCE-72EL2418SSF | 72.00 | 24.00 | 18.00 | IS6 |
| SCE-72EL2424SSF | 72.00 | 24.00 | 24.00 | IS6 |
| SCE-72EL3018SSF | 72.00 | 30.00 | 18.00 | IS6 |
| SCE-72EL3024SSF | 72.00 | 30.00 | 24.00 | IS6 |
| SCE-72EL3618SSF | 72.00 | 36.00 | 18.00 | IS6 |
| SCE-72EL3624SSF | 72.00 | 36.00 | 24.00 | IS6 |
| SCE-72EL3630SSF | 72.00 | 36.00 | 30.00 | IS6 |
| SCE-72EL3636SSF | 72.00 | 36.00 | 36.00 | IS6 |
| SCE-90EL2420SSF | 90.00 | 24.00 | 20.00 | IS6 |
| SCE-90EL3620SSF | 90.00 | 36.00 | 20.00 | IS6 |
| SCE-90EL3624SSF | 90.00 | 36.00 | 24.00 | IS6 |
| SCE-90EL3636SSF | 90.00 | 36.00 | 36.00 | IS6 |

316 STAINLESS STEEL

Enclosure Product Code S4

| Catalog No. | Height (A) | Width (B) | Depth (C) | Industry Standard |
|-----------------------------------|------------|-----------|-----------|-------------------|
| SCE-60EL2418SS6FS | 60.00 | 24.00 | 18.00 | IS6 |
| SCE-60EL3624SS6FS | 60.00 | 36.00 | 24.00 | IS6 |
| SCE-72EL2418SS6FS | 72.00 | 24.00 | 18.00 | IS6 |
| SCE-72EL2424SS6FS | 72.00 | 24.00 | 24.00 | IS6 |
| SCE-72EL3018SS6FS | 72.00 | 30.00 | 18.00 | IS6 |
| SCE-72EL3024SS6FS | 72.00 | 30.00 | 24.00 | IS6 |
| SCE-72EL3618SS6FS | 72.00 | 36.00 | 18.00 | IS6 |
| SCE-72EL3624SS6FS | 72.00 | 36.00 | 24.00 | IS6 |
| SCE-72EL3630SS6FS | 72.00 | 36.00 | 30.00 | IS6 |
| SCE-72EL3636SS6FS | 72.00 | 36.00 | 36.00 | IS6 |
| SCE-90EL2420SS6FS | 90.00 | 24.00 | 20.00 | IS6 |
| SCE-90EL3620SS6FS | 90.00 | 36.00 | 20.00 | IS6 |
| SCE-90EL3624SS6FS | 90.00 | 36.00 | 24.00 | IS6 |
| SCE-90EL3636SS6FS | 90.00 | 36.00 | 36.00 | IS6 |

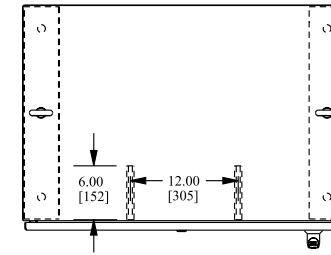

LATCH NOTE:
OMIT CENTER LATCH TOP
AND BOTTOM OF DOOR WHEN
DOOR WIDTH IS < 30.00 [762]

