

Application

Designed to house electrical equipment and provide degree of protection from dirt, dust, oil and water and to house most standard type disconnects. For installation information, consult our installation manual at www.saginawcontrol.com.

Construction

- 0.104" stainless steel Type 304.
- Seams continuously welded and ground smooth.
- Flange trough collar around all sides of door opening.
- Body stiffeners in large enclosures for extra rigidity.
- Heavy duty lifting eyes anchor into reinforced top.
- Stainless steel concealed hinges.
- Black zinc die cast coinproof/padlocking handle.
- 3-point latching mechanism.
- Black quarter turn latches as required.
- Panel supports.
- Large removable print pockets.
- Pour in place oil and water resistant gasket.
- Removable subpanels mount on collar studs.
- Defeater on master door requires a screwdriver to open.
- Ground stud on door and body.
- Provisions for light kit.


Finish

#4 brushed finish on all exterior surfaces. Disconnect switch (or circuit breaker) and operating mechanism are not furnished with this enclosure.

IS6 Industry Standards

- NEMA Type 3R, 4, 4X, 12 & Type 13
- UL Listed Type 3R, 4, 4X & 12
- CSA Type 3R, 4, 4X & 12
- IEC 60529 IP66

***To maintain Type 3R listing, drainage is required. Install equally rated drainage device or drill a 1/8 to 1/4 inch hole in the bottom center of the enclosure, approximately 1 inch from the right, and 1 inch from the left for drainage, use listed rain-tight or wet location hubs. Drip shield over the door is recommended for all outdoor applications.

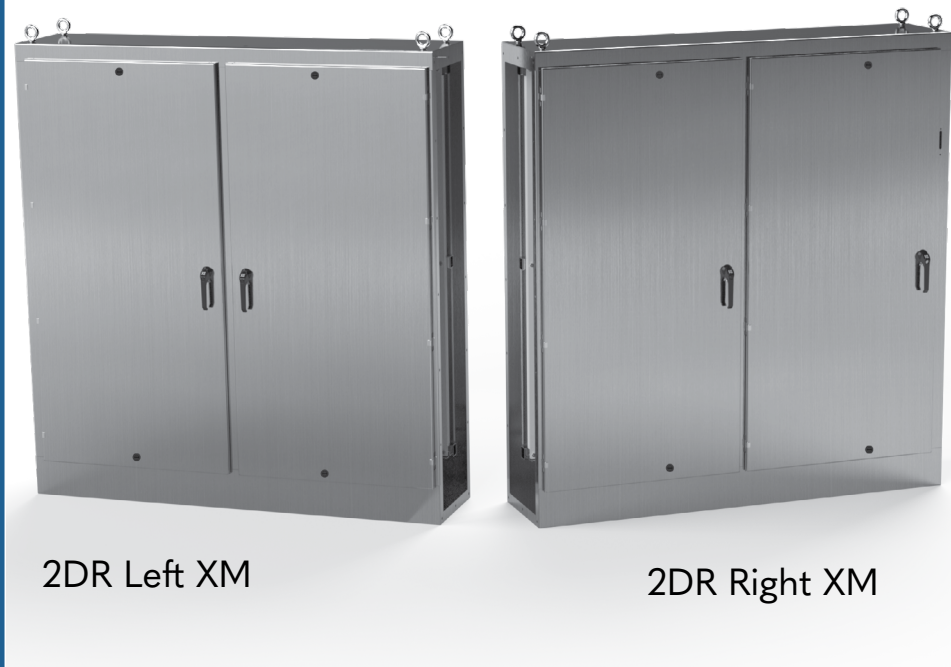


2DR Left XM

2DR Right XM

XM ENCLOSURES

* Add the letter U to the end of the part number for enclosures with a universal disconnect cutout.

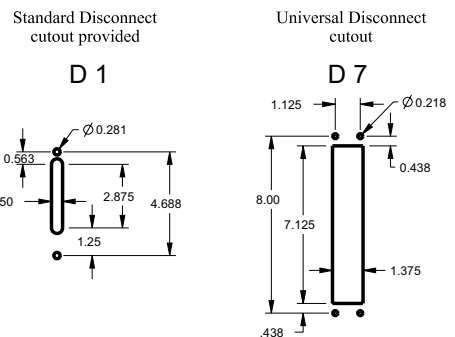

FOUR-DOOR ENCLOSURES 304 STAINLESS STEEL

Enclosure Product Code S2

Catalog No.	Height (A)	Width (B)	Depth (C)	Subpanel (P3)		
				Catalog No.	Panel Height (D)	Panel Width (E)
SCE-72XM4EW18SS	72	157.5	18			
Equals Qty 1 Part# SCE-72XMR2D18SS	72	78.75	18	SCE-64P76	60	72
Equals Qty 1 Part# SCE-72XML2D18SS	72	78.75	18	SCE-64P76	60	72
SCE-84XM4EW18SS	84	157.5	18			
Equals Qty 1 Part# SCE-84XMR2D18SS	84	78.75	18	SCE-76P76	72	72
Equals Qty 1 Part# SCE-84XML2D18SS	84	78.75	18	SCE-76P76	72	72
SCE-84XM4EW18SSG	84	157.5	18			
Equals Qty 1 Part# SCE-84XMR2D18SSG	84	78.75	18	SCE-76P76GALV	72	72
Equals Qty 1 Part# SCE-84XML2D18SSG	84	78.75	18	SCE-76P76GALV	72	72
SCE-84XM4EW24SS	84	157.5	24			
Equals Qty 1 Part# SCE-84XMR2D24SS	84	78.75	24	SCE-76P76	72	72
Equals Qty 1 Part# SCE-84XML2D24SS	84	78.75	24	SCE-76P76	72	72
SCE-84XM4EW24SSG	84	157.5	24			
Equals Qty 1 Part# SCE-84XMR2D24SSG	84	78.75	24	SCE-76P76GALV	72	72
Equals Qty 1 Part# SCE-84XML2D24SSG	84	78.75	24	SCE-76P76GALV	72	72
SCE-90XM4EW18SS	90	157.5	18			
Equals Qty 1 Part# SCE-90XMR2D18SS	90	78.75	18	SCE-82P76	78	72
Equals Qty 1 Part# SCE-90XML2D18SS	90	78.75	18	SCE-82P76	78	72
SCE-90XM4EW24SS	90	157.5	24			
Equals Qty 1 Part# SCE-90XMR2D24SS	90	78.75	24	SCE-82P76	78	72
Equals Qty 1 Part# SCE-90XML2D24SS	90	78.75	24	SCE-82P76	78	72
SCE-90XM4EW24SSU	90	157.5	24			
Equals Qty 1 Part# SCE-90XMR2D24SSU	90	78.75	24	SCE-82P76	78	72
Equals Qty 1 Part# SCE-90XML2D24SSU	90	78.75	24	SCE-82P76	78	72