

# ENVIRO-THERM® THERMAL MANAGEMENT


## TYPE 12 FANS & FILTERS - BLACK

Easy to install snap fit design for use in enclosures that require cooling but have limited space in NEMA 1 and 12 applications. Housing and grille are made of black heat resistant (ABS-FR), self-extinguishing material. Fans are available in 115, 230 or 460 volt AC, 50/60 Hertz (Hz) single phase or 24 volt DC.

UL Listed Type 12



Catalog No.	Height (A)	Width (B)	Depth (C)	CFM	Cutout Size (F)	Product Code
<a href="#">SCE-N12FA33</a>	4.20	4.20	3.10	13/15	3.75 sq.	P1
<a href="#">SCE-N12FA33-230</a>	4.20	4.20	3.10	13/15	3.75 sq.	P1
<a href="#">SCE-N12FA33-24VDC</a>	4.20	4.20	3.10	20	3.75 sq.	P1
<a href="#">SCE-N12FA44</a>	5.91	5.91	2.88	26/29	5.03 sq.	P1
<a href="#">SCE-N12FA44-230</a>	5.91	5.91	2.88	39/47	5.03 sq.	P1
<a href="#">SCE-N12FA44-24VDC</a>	5.91	5.91	2.88	28	5.03 sq.	P1
<a href="#">SCE-N12FA66</a>	9.84	9.84	4.91	135/159	8.91 sq.	P1
<a href="#">SCE-N12FA66-230</a>	9.84	9.84	4.40	135/159	8.91 sq.	P1
<a href="#">SCE-N12FA66-24VDC</a>	9.84	9.84	4.40	86	8.91 sq.	P1
<a href="#">SCE-N12FA1010</a>	12.80	12.80	6.30	306/341	11.57 sq.	P1
<a href="#">SCE-N12FA1010-230</a>	12.80	12.80	6.30	306/341	11.57 sq.	P1
<a href="#">SCE-N12FA10HF</a>	12.80	12.80	6.24	483/547	11.57 sq.	P1
<a href="#">SCE-N12FA10HF-230</a>	12.80	12.80	6.27	483/547	11.57 sq.	P1
<a href="#">SCE-N12FA10HF-460</a>	12.80	12.80	6.24	483/547	11.57 sq.	P1

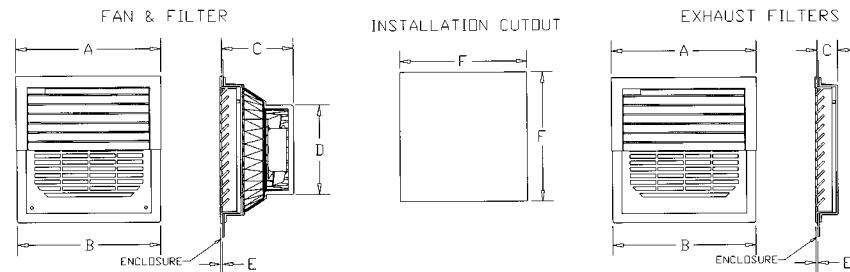


## TYPE 12 FANS & FILTERS - RAL 7035 GRAY

Easy to install snap fit design for use in enclosures that require cooling but have limited space in NEMA 1 and 12 applications. Housing and grille are made of gray heat resistant (ABS-FR), self-extinguishing material. Fans are available in 115, 50/60 Hertz (Hz) single phase or 24 volt DC.

UL Listed Type 12



Catalog No.	Height (A)	Width (B)	Depth (C)	CFM	Cutout Size (F)	Product Code
<a href="#">SCE-N12FA33LG</a>	4.20	4.20	3.14	13/15	3.75 sq.	P1
<a href="#">SCE-N12FA33-230LG</a>	4.20	4.20	3.10	13/15	3.75 sq.	P1
<a href="#">SCE-N12FA33-24VLG</a>	4.20	4.20	3.10	20	3.75 sq.	P1
<a href="#">SCE-N12FA44LG</a>	5.90	5.90	2.90	26/29	5.03 sq.	P1
<a href="#">SCE-N12FA44-24VLG</a>	5.90	5.90	2.90	28	5.03 sq.	P1
<a href="#">SCE-N12FA66LG</a>	9.80	9.80	4.90	135/159	8.91 sq.	P1
<a href="#">SCE-N12FA66-24VLG</a>	9.80	9.80	4.90	86	8.91 sq.	P1
<a href="#">SCE-N12FA1010LG</a>	12.80	12.80	6.30	306/341	11.57 sq.	P1

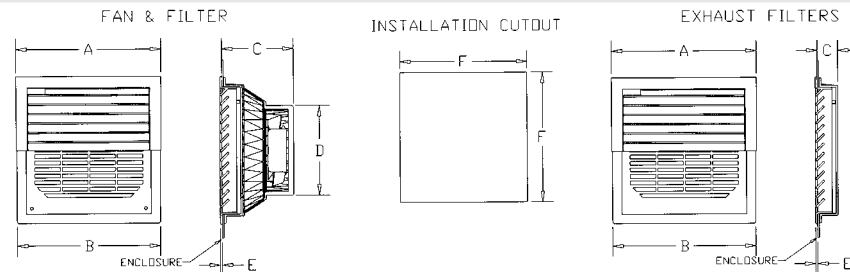

## TYPE 12 EXHAUST FILTERS - BLACK

Easy to install snap fit design for use on air discharge side of cooling fan package for Type 1 & 12 applications. Housing and grille are made of black heat resistant (ABS-FR), self-extinguishing material with a Type 12 filter.

UL Listed Type 12

Catalog No.	Height (A)	Width (B)	Depth (C)	Cutout Size (F)	Product Code
<a href="#">SCE-N12FGA33</a>	4.20	4.20	0.50	3.75	P1
<a href="#">SCE-N12FGA44</a>	5.91	5.91	1.15	5.03 Sq.	P1
<a href="#">SCE-N12FGA66</a>	9.84	9.84	1.33	8.91 Sq.	P1
<a href="#">SCE-N12FGA1010</a>	12.8	12.8	1.34	11.57 Sq.	P1



## TYPE 3R FANS & FILTERS

Easy to install snap fit design for use in enclosures that require cooling but have limited space in NEMA 3R applications. Grille is made of black UV and water resistant, self-extinguishing PVC material. Housing is ABS material with steel inner guard for increased impact resistance. Fans are available in 115, 230 volt AC, 50/60 (Hz).

UL Listed Type 3R

Catalog No.	Height (A)	Width (B)	Depth (C)	Cutout Size (F)	Product Code
<a href="#">SCE-N12FGA33LG</a>	4.19	4.19	0.91	3.75	P1
<a href="#">SCE-N12FGA44LG</a>	5.91	5.91	1.15	5.03 Sq.	P1
<a href="#">SCE-N12FGA66LG</a>	9.84	9.84	1.33	8.91 Sq.	P1
<a href="#">SCE-N12FGA1010LG</a>	12.80	12.80	1.34	11.57 Sq.	P1

## TYPE 12 EXHAUST FILTER - RAL 7035 GRAY

Easy to install snap fit design for use on air discharge side of cooling fan package for Type 1 & 12 applications. Housing and grille are made of gray heat resistant (ABS-FR), self-extinguishing material with a Type 12 filter.

UL Listed Type 12


## TYPE 3R EXHAUST FILTERS

Easy to install snap fit design for use on air discharge side of cooling fan package for Type 3R applications. Grille is made of black UV and water resistant, self-extinguishing PVC material. Housing is ABS material with steel inner guard for increased impact resistance.

UL Listed Type 3R

Catalog No.	Height (A)	Width (B)	Depth (C)	CFM	Cutout Size (F)	Product Code
<a href="#">SCE-N3RFA33</a>	4.20	4.20	3.10	13/15	3.75 sq.	P1
<a href="#">SCE-N3RFA33-230</a>	4.20	4.20	3.50	13/15	3.75 sq.	P1
<a href="#">SCE-N3RFA44</a>	5.90	5.90	2.90	39/47	5.03 sq.	P1
<a href="#">SCE-N3RFA44-230</a>	5.90	5.90	2.90	39/47	5.03 sq.	P1
<a href="#">SCE-N3RFA66</a>	9.80	9.80	4.90	133/158	8.91 sq.	P1
<a href="#">SCE-N3RFA66-230</a>	9.80	9.80	4.90	133/158	8.91 sq.	P1
<a href="#">SCE-N3RFA1010</a>	12.80	12.80	6.30	306/341	11.57 sq.	P1
<a href="#">SCE-N3RFA1010-230</a>	12.80	12.80	6.30	306/359	11.57 sq.	P1
<a href="#">SCE-N3RFA10HF</a>	12.80	12.80	6.30	435/494	11.57 sq.	P1
<a href="#">SCE-N3RFA10HF-230</a>	12.80	12.80	6.30	435/494	11.57 sq.	P1

Catalog No.	Height (A)	Width (B)	Depth (C)	Cutout Size (F)	Product Code
<a href="#">SCE-N3RFGA33</a>	4.20	4.20	2.00	3.75	P1
<a href="#">SCE-N3RFGA44</a>	5.90	5.90	1.20	5.03 Sq.	P1
<a href="#">SCE-N3RFGA66</a>	9.80	9.80	1.30	8.91 Sq.	P1
<a href="#">SCE-N3RFGA1010</a>	12.80	12.80	1.30	11.57 Sq.	P1

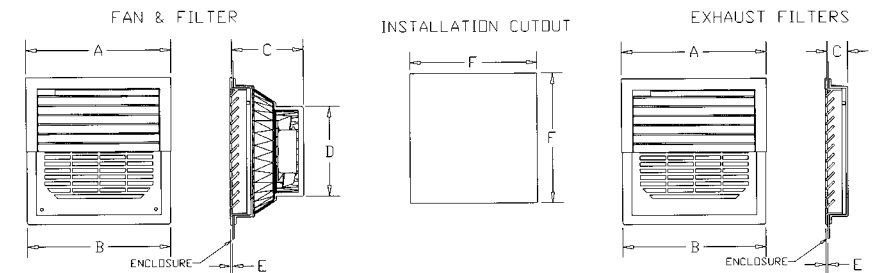

Catalog No.	Height (A)	Width (B)	Depth (C)	Cutout Size (F)	Cutout Size (G)	CFM	Product Code
<a href="#">SCE-FA44</a>	6.11	7.38	3.28	5.66	5.91	63/75	P1
<a href="#">SCE-FA44-230</a>	6.11	7.38	3.28	5.66	5.91	63/75	P1
<a href="#">SCE-FA44-24VDC</a>	6.11	7.38	3.28	5.66	5.91	155	P1
<a href="#">SCE-FA66</a>	7.61	8.88	3.75	7.16	7.41	135/158	P1
<a href="#">SCE-FA66-230</a>	7.61	8.88	3.75	7.16	7.41	135/158	P1
<a href="#">SCE-FA66-24VDC</a>	7.61	8.88	3.75	7.16	7.41	155	P1
<a href="#">SCE-FA1010</a>	11.62	12.88	5.25	11.16	11.41	400/440	P1
<a href="#">SCE-FA1010-230</a>	11.62	12.88	5.25	11.16	11.41	400/440	P1
<a href="#">SCE-FA1010-24VDC</a>	11.62	12.88	5.25	11.16	11.41	425	P1

## FAN PACKAGE

Designed for use in enclosures that require cooling but have limited space. Consists of a washable aluminum filter, steel air plenum, removable stainless steel grille, single phase fan, and approximately 14 inches of lead wire. Grille has captivated thumb nuts for easy access to the filter from the outside. Fans are available in 115 or 230 volt AC or 24 volt DC, 50/60 Hertz (Hz) single phase. Air plenum is ANSI-61 gray powder coated. For installation information, please consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com). UL listed motor.

