


## KEYLOCK BOX

Catalog No.	Height (A)	Width (B)	Depth (C)	Product Code
<a href="#">SCE-KLB</a>	9.38	3.25	1.88	P2

The keylock box is used to hold and secure a common key for a given set of equipment in the plant. This key is secured in the keylock box allowing up to 6 locks for security to access.

Large viewing window in the cover provides clear visibility of the key inside.


Large key tag with key ring included with the keylock box.

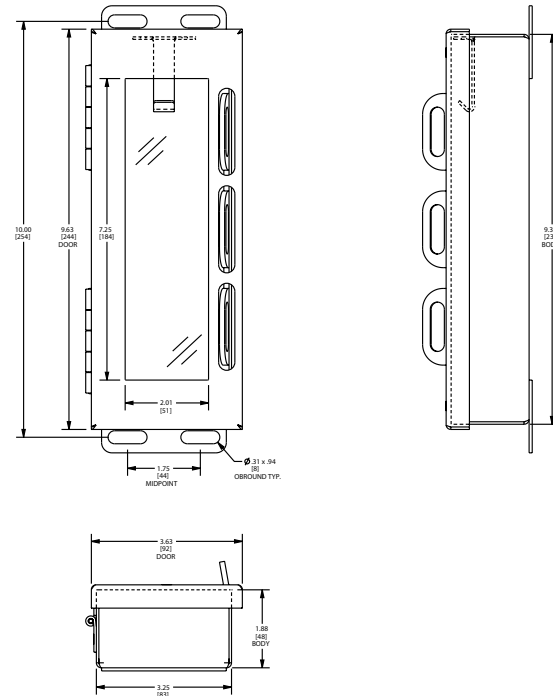

## ORANGE CAUTION LABELS

Safety Orange vinyl Caution Label with Warning Symbols designed for use on interior door for high visibility and warning of potential hazard. Made of high quality durable vinyl, water and oil resistant, with adhesive back for quick easy installation. The vivid safety orange and yellow with the standard Hazard Safety Symbols make them extremely effective in any application.

Catalog No.	Height	Width	Qty. Per Package	Product Code
<a href="#">SCE-OCL12</a>	12.00	12.00	5	P2
<a href="#">SCE-OCL24</a>	24.00	24.00	5	P2

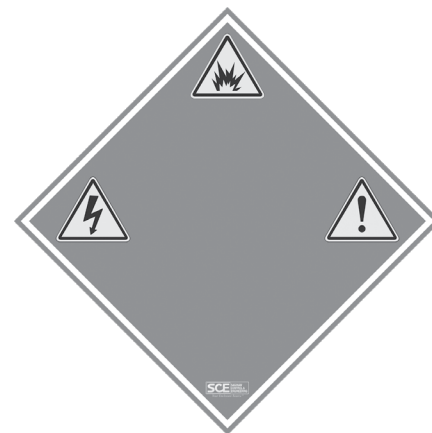

## GASKET ROLLS

Pour in place oil and water resistant gasket made of a urethane closed cell sponge material. Self adhesive backing. For installation information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com). UL, CSA recognized.

IS9 - Industry Standards -  
UL Component Recognized  
CSA Component Recognized

Catalog No.	Length	Flange Type	Quantity	Enclosure Gauge	Product Code
<a href="#">SCE-127617</a>	2.37	90°	2	11 & 12	P2
<a href="#">SCE-128380</a>	2.37	15°	2	14	P

Catalog No.	Length	Size	Product Code
<a href="#">SCE-GA14X1</a>	40 Feet	0.25 x 1.00	P2
<a href="#">SCE-GA14X75</a>	50 Feet	0.25 x 0.75	P2
<a href="#">SCE-GA18X50</a>	50 Feet	0.13 x 0.50	P2

## EMI/RFI SHIELDED GASKET

Specifically designed to combine outstanding attenuation characteristics and environmental protection against dust, dirt, moisture, and severe temperature variations. For technical information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com). Made of urethane foam wrapped in nickel plated copper fabric with adhesive backing.

Catalog No.	Length	Size	Product Code
<a href="#">SCE-SLT</a>	50 Feet	3 MILS x 1.00	P2

Catalog No.	Length	Size	Product Code
<a href="#">SCE-EMIG</a>	7 Feet	0.25 x 1.00	P2

**CENTER CHANNEL GASKET**  
Designed for use with standard 3.5" center channels to maintain a water tight seal.

## CONDUCTIVE TAPE

Copper foil tape with conductive adhesive backing. Makes it unnecessary to plate an enclosure in preparation for shielding protection. Apply the tape over unprotected steel in a small free area around the perimeter of the door. Provides protection to the steel against corrosion and rusting as well as grounding protection necessary in shielding protection.

## MECHANICAL DEFEATER FOR V-STYLE DISCONNECTS

Designed to prevent the disconnect from being turned to the on position, until the master door is shut and the handle or latch is in the closed/latched position. Works with most standard disconnect enclosures with SCE 3-point door hardware or quarter turn latches. For technical information, consult our installation manual at [www.saginawcontrol.com](http://www.saginawcontrol.com).

Catalog No.	Description	Product Code
<a href="#">SCE-MDV</a>	Mechanical Defeater	P2
<a href="#">SCE-MDV400</a>	Mechanical Defeater 400 amp	P2

