

Product data sheet

Specifications

Socket, SE Relays, 30A, 6 pins,
screw connectors, separate contact,
for 725 power relay



70-725-1

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Product Range	Harmony Electromechanical Relays
Product Type	Socket
Number of Terminals	6
Switch Function	DPST
Contact Composition	2 NO

Complementary

Rated Current	30 A
[Ue] rated operational voltage	300 V
Connections Terminals	screw terminal, clamping connection capacity:6 mm ² , AWG 10 solid screw terminal, clamping connection capacity:2 x 0.5...2 x 6 mm ² , AWG 20...AWG 10 stranded
Tightening Torque	Screw 1.2 N.m
Fixing Mode	Clip-on 35 mm symmetrical DIN rail
Product Weight	2.4 oz (67 g)
Depth	2.8 in (70.5 mm)

Environment

Flame Retardance	UL94-V0
------------------	---------

Ordering and shipping details

Category	US10CP221127
Discount Schedule	0CP2
GTIN	3606480277986
Returnability	No
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.79 in (7.08 cm)
Package 1 Width	2.13 in (5.4 cm)
Package 1 Length	0.93 in (2.35 cm)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Package 1 Weight

2.4 oz (67 g)

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard	Yes
--	-----

Packaging without single use plastic	Yes
--------------------------------------	-----


Use Again

Repack and remanufacture

Take-back	No
-----------	----


Dimensions Drawings

Dimensions

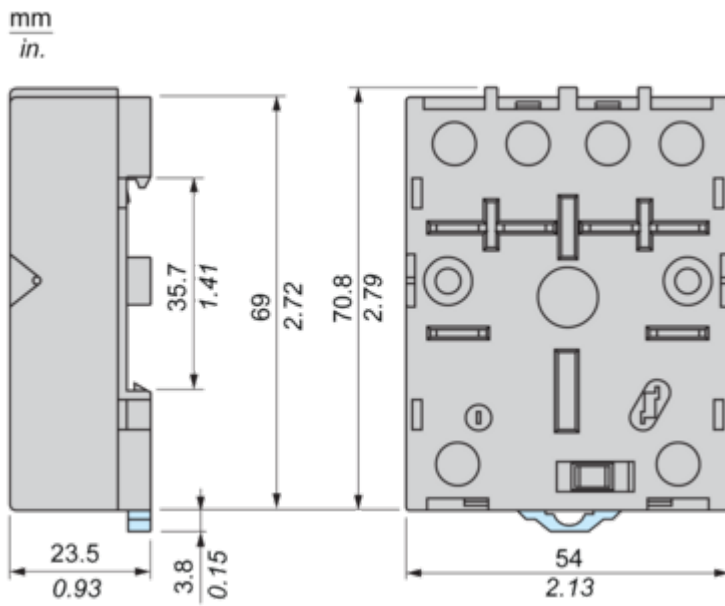

Connections and Schema

Wiring Diagram

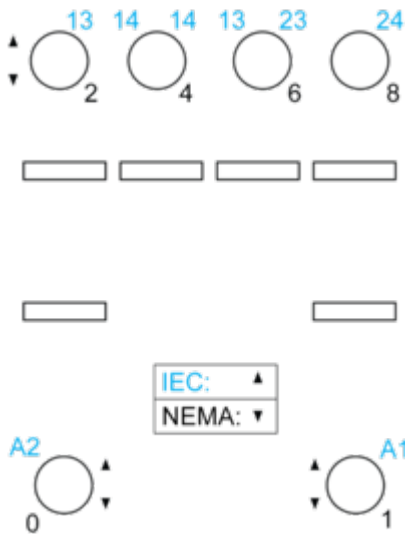

Technical Illustration

Dimensions

