



TR100VA002 | Transformer 100 VA, 120 to 24 Vac, Circuit Breaker, Foot and Dual Threaded Hub Mount

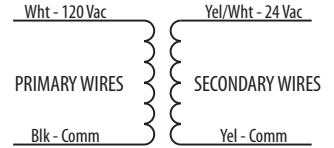


SPECIFICATIONS

- VA Rating:** 100
- Frequency:** 50/60 Hz
- Mounting:** Foot & Dual Threaded Hubs
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.000" x 2.500" x 4.000"
(w/ .500" NPT Hubs)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 4.13 lbs.
- Approvals:** Class II UL1585 Listed, C-UL, CE

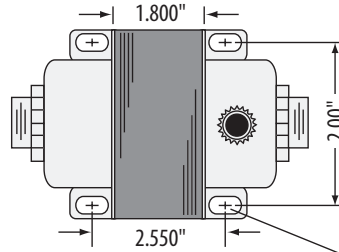

Mounting Hole = .350" x .175"

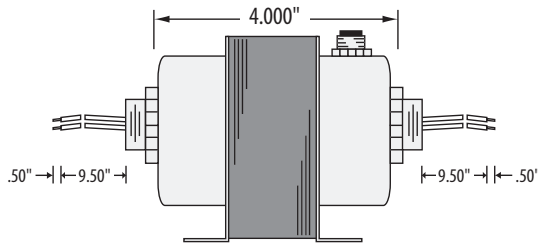

NOTES