



TR150VA001 | Transformer 150 VA, 120 to 24 Vac, Circuit Breaker, Foot and Single Threaded Hub Mount


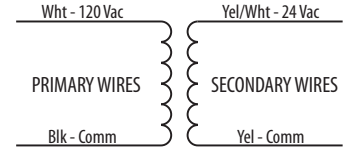


SPECIFICATIONS

- VA Rating:** 150
- Frequency:** 50/60 Hz
- Mounting:** Foot & Single Threaded Hub
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.250" x 3.790" x 3.500"
(w/ .500" NPT Hub)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 4.92 lbs.
- Approvals:** UL506 Listed General Purpose
C-UL, CE

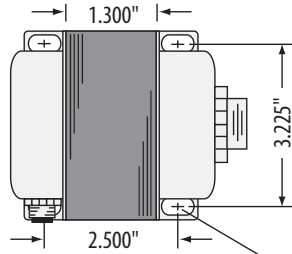

Mounting Hole = .400" x .200"

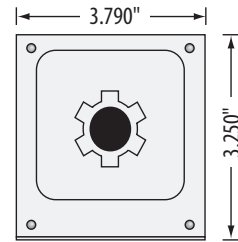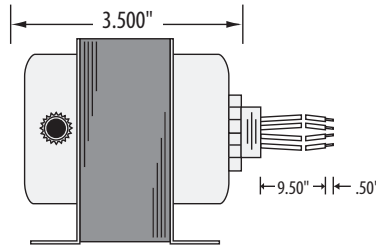

NOTES