



TR20VA002 | Transformer 20 VA, 208 to 24 Vac, Foot and Dual Threaded Hub Mount

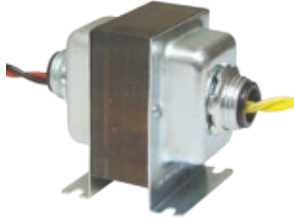

SPECIFICATIONS

- VA Rating: 20
- Frequency: 50/60 Hz
- Mounting: Foot & Dual Threaded Hub
- Over Current Protection: Inherently Limited
- Dimensions: 2.625" x 1.890" x 2.310"
(w/ .500" NPT Hubs)
- Wire Length: 8" Typical w/ .5" Strip
- Operating Temperature: -30 to 140° F
- MTBF: 100,000 Hours @ 77° F
- Construction: Split-Bobbin
- Weight: 1.32 lbs.
- Approvals: Class II UL1585 Listed, C-UL, CE

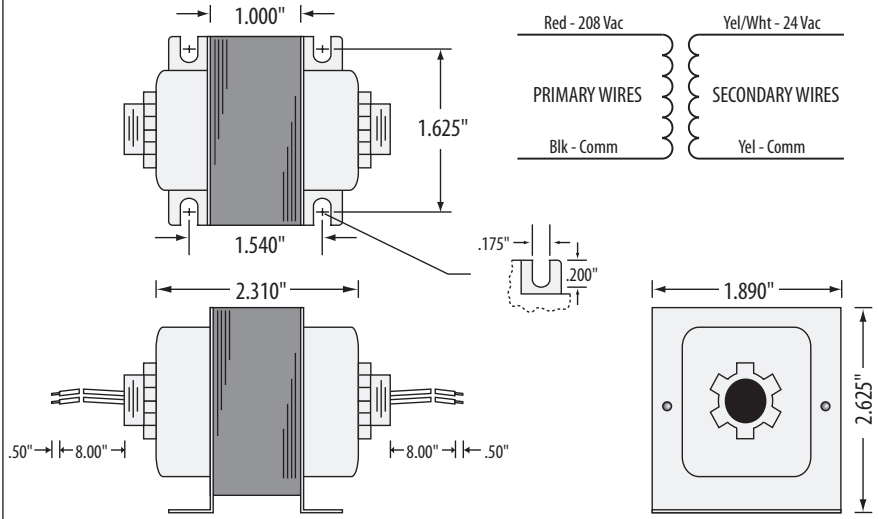

NOTES