



TR50VA009 | Transformer 50 VA, 240/208/120 to 24 Vac, Circuit Breaker, Foot and Dual Threaded Hub Mount


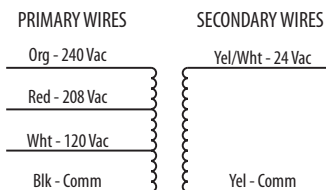


SPECIFICATIONS

- VA Rating: 50
- Frequency: 50/60 Hz
- Mounting: Foot & Dual Threaded Hubs
- Over Current Protection: Circuit Breaker
- Dimensions: 3.000" x 2.525" x 3.475"
(w/ .500" NPT Hubs)
- Wire Length: 9.5" Typical w/ .5" Strip
- Operating Temperature: -30 to 140° F
- MTBF: 100,000 Hours @ 77° F
- Construction: Split-Bobbin
- Weight: 2.82 lbs.
- Approvals: Class II UL1585 Listed, C-UL, CE

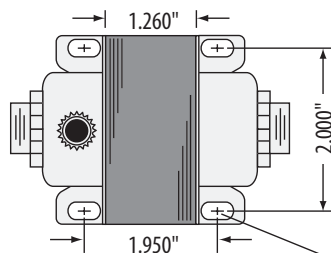

Mounting Hole = .350" x .175"

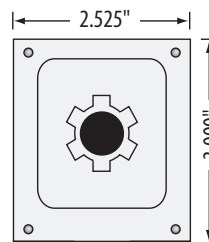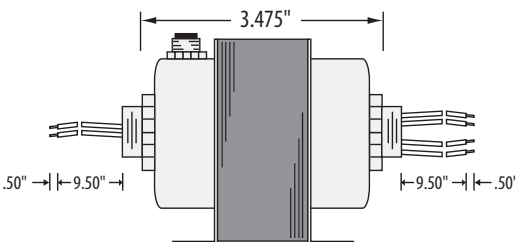

NOTES