



TR50VA016 | Transformer 50 VA, 240/208/120 to 24 Vac, Circuit Breaker, Foot and Single Threaded Hub Mount


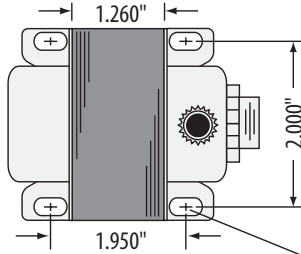


Mounting Hole = .350" x .175"

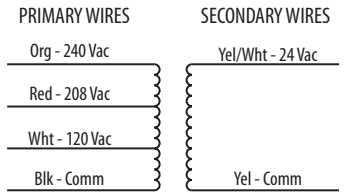

SPECIFICATIONS

- VA Rating:** 50
- Frequency:** 50/60 Hz
- Mounting:** Foot & Single Threaded Hubs
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.060" x 2.525" x 3.475"
(w/ .500" NPT Hubs)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 2.90 lbs.
- Approvals:** Class II UL1585 Listed, C-UL, CE

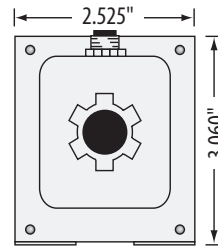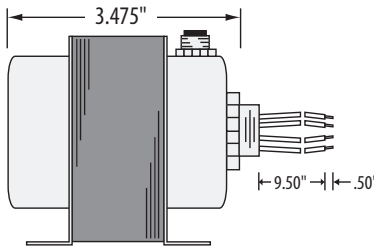

NOTES