


### Socket Specifications

Part Number	70-788EL11-1
Contact Configuration	3PDT
Number of Terminals	11
Mounting Style	DIN rail
Current Rating	25 A
Nominal Voltage Rating	300 V
Temperature Storage Range	-40 – +105 °C (-40 – +221 °F)
Protection Category (Finger-safe™)	IP 20
Internal Metal Tracks	Copper Alloy, Zinc Plated
Screw Terminals	Steel, Zinc Plated
Screw Style	Combination Head
Screw Size	M3.5 mm
Maximum Screw Torque	9 Lb-in / 1.0 N•m
Terminal Connection	Elevator
Terminal Layout	Separate
Maximum Wire Size	<b>Solid Cu:</b> 10 / 14 (2) AWG, 6 / 2.5 (2) mm <sup>2</sup> <b>Stranded Cu:</b> 10 / 14 (2) AWG, 6 / 2.5 (2) mm <sup>2</sup>
DIN Rail Mounting, EN 60715	35 mm
Chassis Mount Screw Torque	7 Lb-in / 0.8 N•m
Flammability Rating	94V-0
Weight	96 g (3.39 oz)
Agency Approvals	UL (E70550), CE, CSA (LR40787), RoHS

### Dimensions — inches (millimeters)

70-788EL11-1

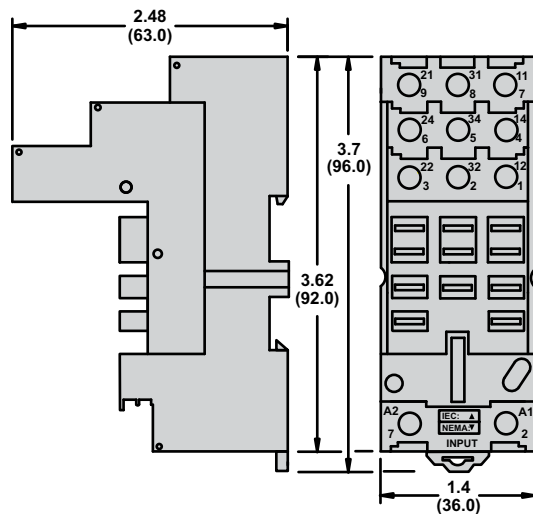

### Wiring Diagram

70-788EL11-1

