 





**Duty:** Standard  
**Rolling Elements:** Ball  
**Housing:** Ductile Iron Two Bolt Flange  
**Self Alignment:** +/- 2 Degrees  
**Lock:** Concentric  
**Lock:** SKWEZLOC Locking Collar  
**Seal:** Felt  
**Optional Seal:** Contact  
**Temperature:** -20° to 220°F

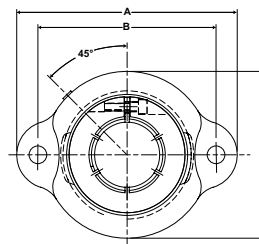

### Options

- 1 Grease Fitting

- 2 Adapter Fitting

## TFT-T Series Standard Duty Two-Bolt Flange Units - SKWEZLOC Locking Collar

| Bore Diameter<br>inch | Part No.           |                     |                      | Part No. | Basic Dynamic Rating<br>lb/N | Dimensions inch / mm |                |               |               |               |                |                |             | Bolt Size | Unit Wt.<br>lb/kg |
|-----------------------|--------------------|---------------------|----------------------|----------|------------------------------|----------------------|----------------|---------------|---------------|---------------|----------------|----------------|-------------|-----------|-------------------|
|                       | Standard With Plug | With Grease Fitting | With Adapter Fitting |          |                              | A                    | B              | C             | D             | H             | K              | L              | N           |           |                   |
| 15/16                 | TFT-15TC           | TFT-15TC-1          | TFT-15TC-2           | 2-015TC  | 2801                         | 3 3/4                | 3              | 2 3/4         | 11/16         | 1 1/2         | 1 7/16         | 1 15/16        | 9/16        | 3/8       | 1.6               |
| 1                     | TFT-16TC           | TFT-16TC-1          | TFT-16TC-2           | 2-1TC    | 12459                        | 95.3                 | 76.2           | 69.9          | 17.5          | 38.1          | 36.5           | 49.2           | 14.3        |           | 0.73              |
| 1 1/8                 | TFT-18TC           | TFT-18TC-1          | TFT-18TC-2           | 2-12TC   | 4381<br>19487                | 4 7/16<br>112.7      | 3 9/16<br>90.5 | 3 1/4<br>82.6 | 13/16<br>20.6 | 1 5/8<br>41.3 | 1 9/16<br>39.7 | 2 3/16<br>55.6 | 5/8<br>15.9 | 3/8       | 2.3<br>1.04       |
| 1 1/5                 | TFT-19TC           | TFT-19TC-1          | TFT-19TC-2           | 2-13TC   |                              |                      |                |               |               |               |                |                |             |           |                   |
| 1 1/4                 | TFT-20RT*          | TFT-20RT*           | TFT-20RT*            | 1-14T    |                              |                      |                |               |               |               |                |                |             |           |                   |
| 1 1/4                 | TFT-20TC           | TFT-20TC-1          | TFT-20TC-2           | 2-14TC   | 5782                         | 4 7/8                | 3 15/16        | 3 11/16       | 7/8           | 1 13/16       | 1 3/4          | 2 7/16         | 11/16       | 3/8       | 3                 |
|                       |                    |                     |                      |          | 25718                        | 123.8                | 100.0          | 93.7          | 22.2          | 46.0          | 44.5           | 61.9           | 17.5        |           | 1.36              |
| 1 3/8                 | TFT-22TC           | TFT-22TC-1          | TFT-22TC-2           | 2-16TC   | 5782                         | 4 7/8                | 3 15/16        | 3 11/16       | 7/8           | 1 13/16       | 1 3/4          | 2 9/16         | 11/16       | 3/8       | 3                 |
| 1 7/16                | TFT-23TC           | TFT-23TC-1          | TFT-23TC-2           | 2-17TC   | 25718                        | 123.8                | 100.0          | 93.7          | 22.2          | 46.0          | 44.5           | 65.1           | 17.5        |           | 1.36              |

For standard duty SKWEZLOC Locking Collar Bearing inserts, see page G-93.

\*1 1/4 Reduced not available with contact seal, felt only.

Metric dimensions for reference only.

Not all parts are available from stock. Please contact customer service for availability (800) 626-2120.

For more information on bearing capabilities outside of our standard offering, please contact Application Engineering (800) 626-2093.