


# Two-Way PICV Assemblies

ANSI Class 250





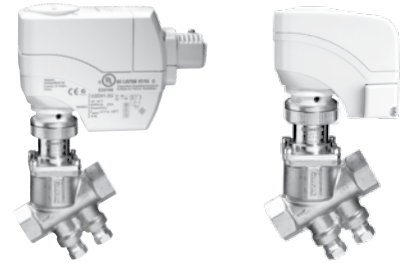



Electronic Spring Return or Non-Spring Return Actuators

- Normally Open
- Field adjustable maximum flow
- 200 psi close-off with ANSI Class IV leakage



A-16

Valves

NO 1/2 to 1-1/4"			Spring Return Actuator		Non-Spring Return Actuator	
			Floating	0-10 V	Floating	0-10 V
2-Way Valve Body Part No.	Valve Size in.	Factory Preset Max. GPM	 SSD81.5U	 SSD61.5U	 SSD81U	 SSD61U
Normally Open						
	1/2	0.5	232-04310-0.5	233-04310-0.5	230-04310-0.5	231-04310-0.5
		1.0	232-04311-1	233-04311-1	230-04311-1	231-04311-1
		1.5	232-04311-1.5	233-04311-1.5	230-04311-1.5	231-04311-1.5
		2.0	232-04311-2	233-04311-2	230-04311-2	231-04311-2
		2.5	232-04311-2.5	233-04311-2.5	230-04311-2.5	231-04311-2.5
	3/4	1.0	232-04312-1	233-04312-1	230-04312-1	231-04312-1
		1.5	232-04312-1.5	233-04312-1.5	230-04312-1.5	231-04312-1.5
		2.0	232-04312-2	233-04312-2	230-04312-2	231-04312-2
		2.5	232-04312-2.5	233-04312-2.5	230-04312-2.5	231-04312-2.5
		3.0	232-04312-3	233-04312-3	230-04312-3	231-04312-3
		3.5	232-04312-3.5	233-04312-3.5	230-04312-3.5	231-04312-3.5
		4.0	232-04312-4	233-04312-4	230-04312-4	231-04312-4
		4.5	232-04312-4.5	233-04312-4.5	230-04312-4.5	231-04312-4.5
		5.0	232-04312-5	233-04312-5	230-04312-5	231-04312-5
5.5	232-04312-5.5	233-04312-5.5	230-04312-5.5	231-04312-5.5		
	1	5	232-04313-5	233-04313-5	230-04313-5	231-04313-5
		6	232-04313-6	233-04313-6	230-04313-6	231-04313-6
		7	232-04313-7	233-04313-7	230-04313-7	231-04313-7
		8	232-04313-8	233-04313-8	230-04313-8	231-04313-8
	1-1/4	9	232-04314-9	233-04314-9	230-04314-9	231-04314-9
		10	232-04314-10	233-04314-10	230-04314-10	231-04314-10
		11	232-04314-11	233-04314-11	230-04314-11	231-04314-11
		12	232-04314-12	233-04314-12	230-04314-12	231-04314-12
		13	232-04314-13	233-04314-13	230-04314-13	231-04314-13
		14	232-04314-14	233-04314-14	230-04314-14	231-04314-14
		15	232-04314-15	233-04314-15	230-04314-15	231-04314-15
		16	232-04314-16	233-04314-16	230-04314-16	231-04314-16
		17	232-04314-17	233-04314-17	230-04314-17	231-04314-17
		18	232-04314-18	233-04314-18	230-04314-18	231-04314-18

**Table Notes:**

Part numbers in red indicate complete assemblies.

