


Two-Way **Globe** Valve Assemblies – MT Series

ANSI Class 250

Electronic Spring Return Actuators

- Normally Open or Normally Closed
- Brass and Stainless Steel Trim

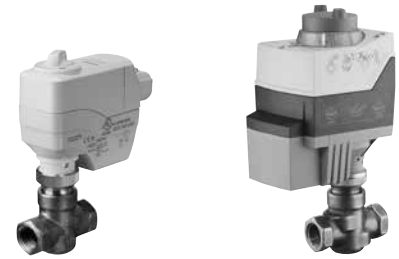









NO/NC 1/2 to 1"			Spring Return Actuator							
			Floating			0-10 V				
2-Way Valve Body Part No.	Valve Size in.	Flow Rate Cv		 NEW!		 NEW!				
			SSC81.5U	SAS81.33U	SSC61.5U	SAS61.33U				
Normally Open										
Close-off psi – Brass Trim										
	1/2	0.4	120	260-02030	160	366-02030	120	262-02030	160	365-02030
		0.63	120	260-02032	160	366-02032	120	262-02032	160	365-02032
		1	120	260-02034	160	366-02034	120	262-02034	160	365-02034
		1.6	120	260-02036	160	366-02036	120	262-02036	160	365-02036
		2.5	65	260-02038	85	366-02038	65	262-02038	85	365-02038
		4	65	260-02041	85	366-02041	65	262-02041	85	365-02041
	3/4	6.3	55	260-02044	70	366-02044	55	262-02044	70	365-02044
	1	10	55	260-02046	70	366-02046	55	262-02046	70	365-02046
	Close-off psi – Stainless Steel Trim									
	1/2	0.4	120	260-02047	160	366-02047	120	262-02047	160	365-02047
		0.63	120	260-02049	160	366-02049	120	262-02049	160	365-02049
		1	120	260-02051	160	366-02051	120	262-02051	160	365-02051
		1.6	120	260-02053	160	366-02053	120	262-02053	160	365-02053
		2.5	65	260-02055	85	366-02055	65	262-02055	85	365-02055
		4	65	260-02058	85	366-02058	65	262-02058	85	365-02058
	3/4	6.3	55	260-02061	70	366-02061	55	262-02061	70	365-02061
	1	10	55	260-02063	70	366-02063	55	262-02063	70	365-02063
	Normally Closed									
Close-off psi – Brass Trim										
	1/2	0.4	95	260-02000	95	366-02000	95	262-02000	95	365-02000
		0.63	95	260-02002	95	366-02002	95	262-02002	95	365-02002
		1	95	260-02004	95	366-02004	95	262-02004	95	365-02004
		1.6	95	260-02006	95	366-02006	95	262-02006	95	365-02006
		2.5	50	260-02008	50	366-02008	50	262-02008	50	365-02008
		4	50	260-02010	50	366-02010	50	262-02010	50	365-02010
	3/4	6.3	40	260-02012	40	366-02012	40	262-02012	40	365-02012
	1	10	40	260-02014	40	366-02014	40	262-02014	40	365-02014
	Close-off psi – Stainless Steel Trim									
	1/2	0.4	95	260-02015	95	366-02015	95	262-02015	95	365-02015
		0.63	95	260-02017	95	366-02017	95	262-02017	95	365-02017
		1	95	260-02019	95	366-02019	95	262-02019	95	365-02019
		1.6	95	260-02021	95	366-02021	95	262-02021	95	365-02021
		2.5	50	260-02023	50	366-02023	50	262-02023	50	365-02023
		4	50	260-02025	50	366-02025	50	262-02025	50	365-02025
	3/4	6.3	40	260-02027	40	366-02027	40	262-02027	40	365-02027
	1	10	40	260-02029	40	366-02029	40	262-02029	40	365-02029

Table Notes:

Part numbers in red indicate complete assemblies. Black numbers indicate close-off psi.



A-25

Valves