

SIRCO DC UL98B

Load break switches for photovoltaic applications

from 100 to 2000 A - up to 1000 VDC

Accessories (continued)

Shaft for external handle

Use

Standard lengths:


- 7.9 in / 200 mm,
- 12.6 in / 320 mm,
- 15.7 in / 400 mm.

Other lengths: Please consult us.



access_369_a_1_cat

access_144_b_1_cat

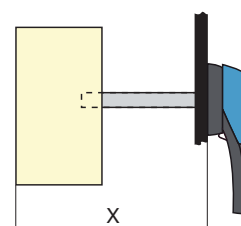

access_202_a_1_X_cat

For 3/4 poles

Rating (A)	Dimension X (inches)	Dimension Y (mm)	Handle	Length (inches)	Length (mm)	Reference
100 ... 200	6 ... 11.6	295	S2 type	7.9	200	1400 1020
100 ... 200	6 ... 16.3	415	S2 type	12.6	320	1400 1032
100 ... 200	6 ... 19.4	495	S2 type	15.7	400	1400 1040
400	8 ... 12.9	203 ... 328	S2 type	7.9	200	1400 1020
400	8 ... 17.6	203 ... 448	S2 type	12.6	320	1400 1032
400	8 ... 20.7	203 ... 528	S2 type	15.7	400	1400 1040
600	8.70 ... 13.50	221 ... 343	S3 type	7.9	200	1401 1520
600	8.70 ... 18.23	221 ... 463	S3 type	12.6	320	1401 1532
600	8.70 ... 21.38	221 ... 543	S3 type	15.7	400	1401 1540
800 ... 1200	12 ... 14.4	221 ... 366	S4 type	7.9	200	1401 1520
800 ... 1200	12 ... 19.1	221 ... 486	S4 type	12.6	320	1401 1532
800 ... 1200	12 ... 22.2	221 ... 566	S4 type	15.7	400	1401 1540
2000	20 ... 28.1	508 ... 714	S5, V1 type	12.6	320	4199 3018
2000	20 ... 39.4	508 ... 794	S5, V1 type	15.7	400	4199 3019

S-type handle adapter

Use

For handles S2, S3 and S4.

Dimensions

Increases the distance between the handle grip and the door by 12 mm, for better handling.

Colour	Nema degree of protection	To be ordered in multiples of	Reference
Black	1, 3R, 12	10	1493 0000



access_187_a_3_cat

Alternative S-type handle cover colours

Use

For handles S2, S3 and S4.

Other colours: Please consult us.

Handle colour	Handle	To be ordered in multiples of	Reference
Light grey	S2, S3 type	50	1401 0001
Dark grey	S2, S3 type	50	1401 0011
Light grey	S4 type	50	1401 0031
Dark grey	S4 type	50	1401 0041



access_198_a_3_cat