

Accessories

Direct handle

Rating (A)	Colour	Handle type	Reference
100 ... 400	Black	1 lever	4199 4012
600 ... 1200	Black	2 lever	2799 7042



access_129_a_1_cat

External handle

Rating (A)	Handle type	Colour	Nema type	Lockable in 3 positions	Reference
100 ... 200	S2	Black	4, 4X	no	142D 2113
100 ... 200	S2	Red/Yellow	4, 4X	no	142E 2113
100 ... 200	S2	Black	1, 3R, 12	no	142F 2113
100 ... 200	S2	Red/Yellow	1, 3R, 12	no	142G 2113
100 ... 200	S2	Black	4, 4X	yes	142D 2813
100 ... 200	S2	Red/Yellow	4, 4X	yes	142E 2813
100 ... 200	S2	Black	1, 3R, 12	yes	142F 2813
100 ... 200	S2	Red/Yellow	1, 3R, 12	yes	142G 2813
260 ... 600	S3	Black	4, 4X	no	143D 3113
260 ... 600	S3	Red/Yellow	4, 4X	no	143E 3113
260 ... 600	S3	Black	1, 3R, 12	no	143F 3113
260 ... 600	S3	Red/Yellow	1, 3R, 12	no	143G 3113
260 ... 600	S3	Black	4, 4X	yes	143D 3813
260 ... 600	S3	Red/Yellow	4, 4X	yes	143E 3813
260 ... 600	S3	Black	1, 3R, 12	yes	143F 3813
260 ... 600	S3	Red/Yellow	1, 3R, 12	yes	143G 3813
800 ... 1200	S4	Black	4, 4X	no	144D 3113
800 ... 1200	S4	Black	1, 3R, 12	no	144E 3113
800 ... 1200	S4	Black	1, 3R, 12	no	144F 3113
800 ... 1200	S4	Red/Yellow	1, 3R, 12	no	144G 3113
800 ... 1200	S4	Black	4, 4X	yes	144D 3813
800 ... 1200	S4	Red/Yellow	4, 4X	yes	144E 3813
800 ... 1200	S4	Black	1, 3R, 12	yes	144F 3813
800 ... 1200	S4	Red/Yellow	1, 3R, 12	yes	144G 3813
800 ... 1200	S5	Black	1, 3R, 12 ⁽¹⁾	no	1453 8113
800 ... 1200	S5	Red/Yellow	1, 3R, 12 ⁽¹⁾	no	1454 8113
800 ... 1200	V1	Black	1, 3R, 12 ⁽¹⁾	no	4199 7149

(1) For 4, 4X please consult us.

Use

The handle interlocking function prevents the user from opening the door of the enclosure when the switch is in the "ON" position.

Opening the door when the switch is in the "ON" position is possible by defeating the interlocking function (Not S5 and V handles) with the use of a tool (authorized persons only).

The interlocking function is restored when the door is re-closed.



access_150_a_1_cat



access_151_a_1_cat



access_152_a_1_cat




access_286_a_2_cat

Shaft for external handle

Rating (A)	Handle type	Length (in)	Length (mm)	Dimension X (in)	Dimension X (mm)	Reference
100 ... 200	S2 type	7.9	200	10 ... 14.3	254 ... 362	1400 1020
100 ... 200	S2 type	12.6	320	10 ... 19	254 ... 482	1400 1032
100 ... 200	S2 type	15.7	400	10 ... 22.1	254 ... 562	1400 1040
260 ... 400	S3 type	7.9	200	12 ... 18.4	305 ... 467	1401 1520
260 ... 400	S3 type	12.6	320	12 ... 23.1	305 ... 587	1401 1532
260 ... 400	S3 type	15.7	400	12 ... 26.3	305 ... 667	1401 1540
260 ... 400	S3 type	7.9	200	20 ... 23.4	508 ... 594	1401 1520
260 ... 400	S3 type	12.6	320	20 ... 28.1	508 ... 714	1401 1532
260 ... 400	S3 type	15.7	400	20 ... 31.3	508 ... 794	1401 1540
800 ... 1200	S4 type	7.9	200	20 ... 23.4	508 ... 594	1401 1520
800 ... 1200	S4 type	12.6	320	20 ... 28.1	508 ... 714	1401 1532
800 ... 1200	S4 type	15.7	400	20 ... 31.3	508 ... 794	1401 1540
800 ... 1200	V1 / S5 type	12.6	320	20 ... 28.1	508 ... 714	4199 3018
800 ... 1200	V1 / S5 type	15.7	400	20 ... 31.3	508 ... 794	4199 3019



access_369_a_1_cat

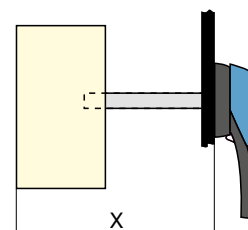

access_202_a_1_x_cat