


460 Δ Primary, 460Y/266 Volt Secondary
 Taps: 1,5% FCAN; 1,5% FCBN

4

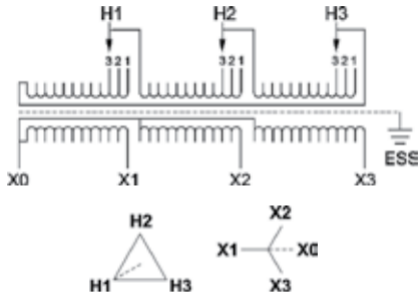

Primary Voltage	H1-H2-H3	Secondary Voltage	
		X1, X2, X3	X0-X1, X2, X3
@ Tap	Voltage		
1	483		
2	460	460	266
3	437		