


460 Δ Primary, 230Y/133 Volt Secondary
 Taps: 1,5% FCAN; 1,5% FCBN

5

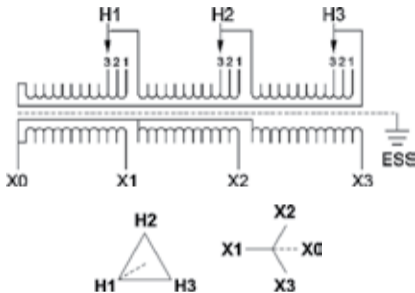

Primary Voltage	H1-H2-H3	Secondary Voltage	
		X1, X2, X3	X0-X1, X2, X3
@ Tap	Voltage		
1	483	230	133
2	460		
3	437		