


Product data sheet

Characteristics

8501XTD2

NEMA Control Relay, Type X, pneumatic timer attachment, three minute off delay, 10A resistive at 600 VAC, 1 NO and 1 NC

Product availability : Non-Stock - Not normally stocked in distribution facility

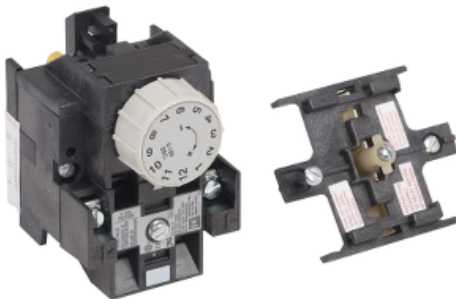

Main

Range of product	8501X
Relay type	Control relay
Product or component type	Timing relay

Complementary

Contacts Configuration	1 NO/1 NC
Time delay type	Off-delay
Time range	5...180 s
Electrical connection	Screw clamp terminals
Wire Gauge	AWG 18...AWG 12 copper
Terminal Tightening Torque	Control circuit 9.03...12.04 lbf.in (1.02...1.36 N.m) screw terminals

Environment

Product certifications	CSA LR60905 class 3211 02 UL recognized E78403 CCN NKCR2 CE
------------------------	---

Ordering and shipping details

Category	21159 - 8501 X ACCESSORIES
Discount Schedule	CP2
GTIN	00785901537373
Nbr. of units in pkg.	1
Package weight(Lbs)	0.79 lb(US) (0.36 kg)

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Returnability	No
Country of origin	MX

Packing Units

Package 1 Height	3.40 in (8.636 cm)
Package 1 width	4.50 in (11.430 cm)
Package 1 Length	6.30 in (16.002 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Contractual warranty

Warranty	18 months
----------	-----------