


Product data sheet

Characteristics

8501XUDO40V63

NEMA Control Relay, Type X, utility, 10A resistive at 600 VAC, 4 normally open contacts, 125 VDC coil

Product availability : Stock - Normally stocked in distribution facility

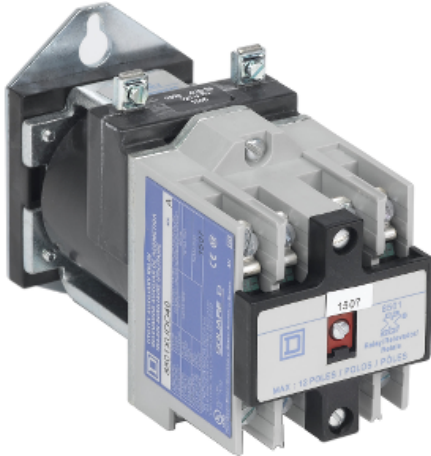

Main

Range	8501X
Relay Type	Utility
Product	Relay
Current Rating	10 A AC 5 A DC
Contact Configuration	4 NO 4 standard contact cartridges
Number of Poles	4P
Coil Voltage	125 V DC
Voltage Rating	250 V DC
Mounting Type	Panel
Operating Temperature	-40...160 °F (-40...71 °C)
Electrical Connection	Screw clamp terminals
Certifications	UL Listed CE CSA
Operating Time	37 ms - pick-up 21 ms - drop-out
Height	3.56 in (90.42 mm)
Width	2.23 in (56.64 mm)
Depth	5.17 in (131.32 mm)

Ordering and shipping details

Category	21157 - 8501 XDO (DC)
Discount Schedule	CP2
GTIN	00785901743316

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Nbr. of units in pkg.	1
Package weight(Lbs)	3.26 lb(US) (1.48 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Package 1 Height	21.59 in (54.839 cm)
Package 1 width	8.50 in (21.590 cm)
Package 1 Length	54.84 in (139.290 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Contractual warranty

Warranty	18 months
----------	-----------