


Product data sheet

Characteristics

8903SMO11V02

Contactor, Type S, multipole lighting,
mechanically held, 30A, 3 pole, 110/120VAC
50/60Hz coil, open style

Product availability : Non-Stock - Not normally stocked in distribution facility

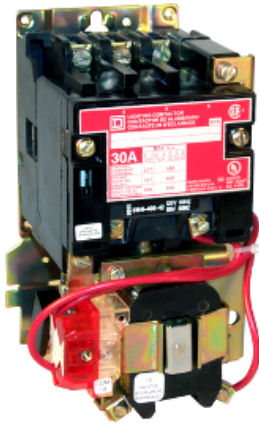

Main

Product	Mechanically Held Lighting Contactor
Type	S

Complementary

Control Circuit Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Current Rating	30 A
Number of Poles	3P
Control Units	No control units
Pilot Light	Without pilot light
Auxiliary Contacts	Without
Other Options	None
Electrical connection	Lugs
Height	6.02 in (153 mm)
Depth	4.69 in (119 mm)
Width	3.78 in (96 mm)

Environment

Enclosure Type	Not rated (open device) surface none
Product certifications	UL Listed CSA

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ordering and shipping details

Category	21324 - 8903 S (NOT S*C) MECH.
Discount Schedule	CP1
GTIN	00785901102458
Nbr. of units in pkg.	1
Package weight(Lbs)	5.91 lb(US) (2.68 kg)
Returnability	No
Country of origin	MX

Packing Units

Package 1 Height	8.70 in (22.098 cm)
Package 1 width	8.30 in (21.082 cm)
Package 1 Length	12.30 in (31.242 cm)

Offer Sustainability

California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Contractual warranty

Warranty	18 months
----------	-----------