


# Product data sheet

## Characteristics

# 8965DPR23V14

Reversing Hoist Contactor, 25 A, 3P, 24 VAC  
50/60 Hz coil, open style

Product availability : Non-Stock - Not normally stocked in distribution facility

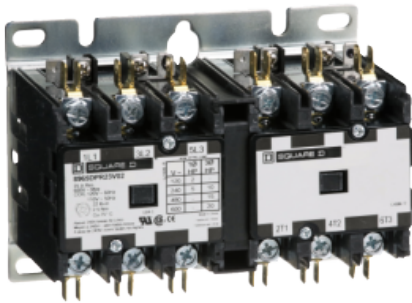

### Main

Product or component type	Reversing Hoist Contactor
Line Rated Current	25 A
Maximum Horse Power Rating	2 hp 115 V AC, 1 phase 3 hp 230 V AC, 1 phase 7.5 hp 230 V AC, 3 phase 10 hp 460 V AC, 3 phase 10 hp 575 V AC, 3 phase

### Complementary

Product certifications	UL Listed CSA
[Ue] rated operational voltage	600 V AC
Poles description	3P
[Uc] control circuit voltage	24 V AC 50/60 Hz
Phase	3 phase
Range of product	DPR

### Ordering and shipping details

Category	21403 - 8965DPR1>DPR4 - 20A>40A REV HOIST
Discount Schedule	CP1
GTIN	00785901081395
Nbr. of units in pkg.	1
Package weight(Lbs)	3.95 lb(US) (1.79 kg)
Returnability	No
Country of origin	CN

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

**Offer Sustainability**

REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.

**Contractual warranty**

Warranty	18 months
----------	-----------