


Product data sheet

Characteristics

9050AO10EV03

Timing Relay, Type A, pneumatic, on delay, 0.1 to 60 seconds, 15A, 600 V, SPDT, timed, 220/240 VAC 50/60 Hz coil, open

Product availability : Non-Stock - Not normally stocked in distribution facility

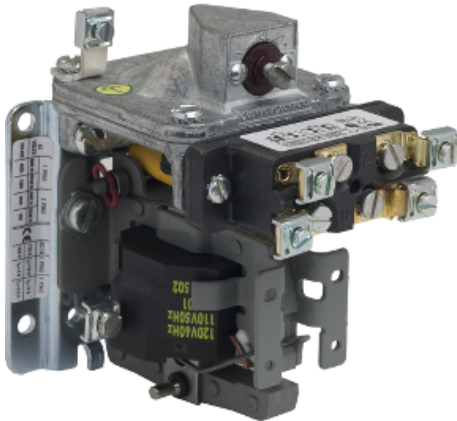

Main

Product range	9050A/H
Product type	Timer
Timing Mode	On-delay
Timing Range	0.1 s...1 min
Switch Function	SPDT
Coil Voltage	240 V AC 60 Hz 220 V AC 50 Hz
Contact Operation	Time delayed 1 NO + 1 NC
Current rating	15 A

Complementary

Maximum switching voltage	600 V AC
Electrical connection	Screw-clamp terminals
Reset response time	29 ms - on-delay 27 ms - off-delay
Mounting Support	Panel

Environment

Ambient Temperature Range - Operational	68...104 °F (20...40 °C)
Certifications	UL Listed CSA
Height	2.64 in (67 mm)
Width	4.02 in (102 mm)

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Depth	4.37 in (111 mm)
-------	------------------

Ordering and shipping details

Category	21631 - 9050 A ONE MINUTE PNEUMATIC TIMER
Discount Schedule	CP1
GTIN	00785901865032
Nbr. of units in pkg.	1
Package weight(Lbs)	1.73 lb(US) (0.78 kg)
Returnability	No
Country of origin	MX

Packing Units

Package 1 Height	2.54 in (6.452 cm)
Package 1 width	1.00 in (2.540 cm)
Package 1 Length	6.45 in (16.387 cm)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Contractual warranty

Warranty	18 months
----------	-----------