


# Product data sheet

## Characteristics

# 9422TF2

Operating mechanism, flange mounted, variable depth, 200A, 600 V, H, K, J, R fuseholder, switch mechanism

Product availability : Non-Stock - Not normally stocked in distribution facility

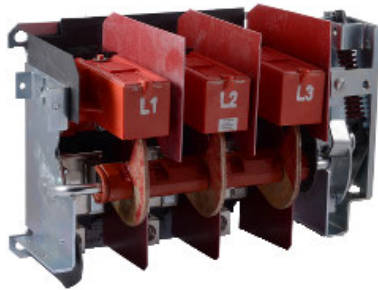

### Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

### Complementary

Mounting Type	Flange rod variable depth
Current Rating	200 A
Horsepower Rating	40 hp 200 V AC 60 hp 230 V AC 125 hp 460 V AC 150 hp 575 V AC 40 hp 250 V DC
Fuse Rating	200 A 250/600 V
Handle Type	Ordered separately
Fuse Type	H K J R

### Environment

Certifications	CSA UL Recognized
----------------	----------------------

### Ordering and shipping details

Category	21732 - 9422
----------	--------------

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Discount Schedule	CP1
GTIN	00785901043744
Nbr. of units in pkg.	1
Package weight(Lbs)	25.38 lb(US) (11.51 kg)
Returnability	No
Country of origin	MX

### Packing Units

Unit Type of Package 1	PCE
Package 1 Height	9.20 in (23.368 cm)
Package 1 width	12.10 in (30.734 cm)
Package 1 Length	20.70 in (52.578 cm)

### Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
PVC free	Yes

### Contractual warranty

Warranty	18 months
----------	-----------