


# Product data sheet

## Characteristics

# 9999D11

Contactor, Definite Purpose, auxiliary contact, 3A at 120 VAC, 1 NO contact and 1 NC contact, for 50A to 90A contactors

Product availability : Stock - Normally stocked in distribution facility

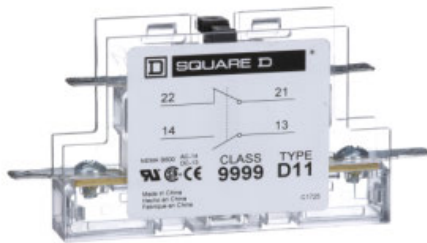

### Main

Product Range	DPA
Component type	Auxiliary Contact Module
Used with	contactor

### Complementary

Auxiliary contact composition	1 NO + 1 NC
Rated breaking capacity	3 A 120 V AC inductive control circuit UL 508 1.5 A 240 V AC inductive control circuit UL 508 0.75 A 480 V AC inductive control circuit UL 508 0.6 A 600 V AC inductive control circuit UL 508 5 A <= 600 V AC resistive control circuit UL 508

### Environment

Product certifications	UL Recognized CSA
------------------------	----------------------

### Ordering and shipping details

Category	21762 - 9999 DISCOUNT CP1B
Discount Schedule	CP1B
GTIN	00785901080886
Nbr. of units in pkg.	1
Package weight(Lbs)	0.09 lb(US) (0.04 kg)
Returnability	Yes
Country of origin	CN

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

## Packing Units

Package 1 Height	0.70 in (1.778 cm)
Package 1 width	1.80 in (4.572 cm)
Package 1 Length	3.70 in (9.398 cm)

## Offer Sustainability

REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.

## Contractual warranty

Warranty	18 months
----------	-----------