


Product data sheet

Characteristics

9999D20

Contactor, Definite Purpose, auxiliary contact, 3A at 120 VAC, 2 NO contacts, for 50A to 90A DPA contactors

Product availability : Stock - Normally stocked in distribution facility

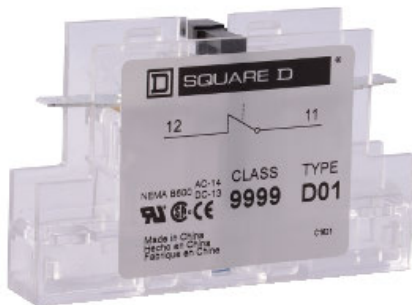

Main

Product Range	DPA
Component type	Auxiliary Contact Module
Used with	contactor

Complementary

Auxiliary contact composition	2 NO
Rated breaking capacity	3 A 120 V AC inductive control circuit UL 508 1.5 A 240 V AC inductive control circuit UL 508 0.75 A 480 V AC inductive control circuit UL 508 0.6 A 600 V AC inductive control circuit UL 508 5 A <= 600 V AC resistive control circuit UL 508

Environment

Product certifications	CSA UL Recognized
------------------------	----------------------

Ordering and shipping details

Category	21762 - 9999 DISCOUNT CP1B
Discount Schedule	CP1B
GTIN	00785901081319
Package weight(Lbs)	0.09 lb(US) (0.04 kg)
Returnability	Yes
Country of origin	CN

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Packing Units

Package 2 Weight	2.66 lb(US) (1.207 kg)
------------------	------------------------

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Contractual warranty

Warranty	18 months
----------	-----------
