


# 9999SX12

Auxiliary contact, Type S, 1 NC contact, internal, nonconvertible

Product availability : Stock - Normally stocked in distribution facility

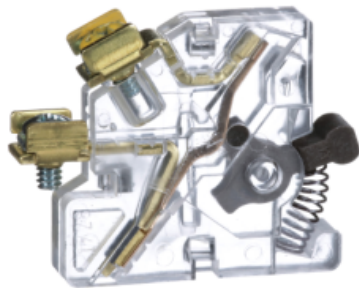

## Main

Product Range	Type S
Component type	Auxiliary Contact Module
Used with	contactor starter

## Complementary

NEMA size	1 0 00 2
Auxiliary contact composition	1 NC
[Uc] control circuit voltage	<= 600 V AC 50/60 Hz
Rated breaking capacity	3 A 120 V AC inductive control circuit UL 508 1.5 A 240 V AC inductive control circuit UL 508 0.75 A 480 V AC inductive control circuit UL 508 0.6 A 600 V AC inductive control circuit UL 508 5 A <= 600 V AC resistive control circuit UL 508

## Environment

Product certifications	CSA UL Recognized UL Listed
------------------------	-----------------------------------

## Ordering and shipping details

Category	21761 - 9999 DISCOUNT CP1
Discount Schedule	CP1
GTIN	00785901879732

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Nbr. of units in pkg.	1
Package weight(Lbs)	0.07 lb(US) (0.03 kg)
Returnability	Yes
Country of origin	MX

### Packing Units

Unit Type of Package 1	PCE
Package 1 Height	1.30 in (3.302 cm)
Package 1 width	2.30 in (5.842 cm)
Package 1 Length	3.00 in (7.62 cm)

### Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Not compliant
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.

### Contractual warranty

Warranty	18 months
----------	-----------