

9999SX6

Auxiliary contact, Type S, 1 NO contact, external, field convertible

Product availability : Stock - Normally stocked in distribution facility



Main

| | |
|----------------|--------------------------|
| Product Range | Type S |
| Component type | Auxiliary Contact Module |
| Used with | contactor starter |

Complementary

| | |
|-------------------------------|---|
| NEMA size | 0 3 6 7 4 5 1 00 2 |
| Auxiliary contact composition | 1 NO |
| [Uc] control circuit voltage | <= 600 V AC 50/60 Hz |
| Rated breaking capacity | 6 A 120 V AC inductive control circuit UL 508 3 A 240 V AC inductive control circuit UL 508 1.2 A 600 V AC inductive control circuit UL 508 1.5 A 480 V AC inductive control circuit UL 508 10 A <= 600 V AC resistive control circuit UL 508 |
| Height | 1.5 in (38.10 mm) |
| Width | 3 in (76.20 mm) |
| Depth | 4.5 in (114.30 mm) |
| Net Weight | 0.20 lb(US) (0.09 kg) |

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Environment

| | |
|------------------------|-----------------------------------|
| Product certifications | CSA UL Listed UL Recognized |
|------------------------|-----------------------------------|

Ordering and shipping details

| | |
|-----------------------|---------------------------|
| Category | 21761 - 9999 DISCOUNT CP1 |
| Discount Schedule | CP1 |
| GTIN | 00785901733300 |
| Nbr. of units in pkg. | 1 |
| Package weight(Lbs) | 0.2 lb(US) (0.09 kg) |
| Returnability | Yes |
| Country of origin | MX |

Packing Units

| | |
|------------------------|-------------------------|
| Unit Type of Package 1 | PCE |
| Package 1 Height | 1.50 in (3.81 cm) |
| Package 1 width | 3.10 in (7.874 cm) |
| Package 1 Length | 4.60 in (11.684 cm) |
| Package 2 Weight | 12.40 lb(US) (5.625 kg) |


Offer Sustainability

| | |
|---------------------------|---|
| California proposition 65 | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov |
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Not compliant |
| China RoHS Regulation | China RoHS declaration Product out of China RoHS scope. Substance declaration for your information. |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Dimensions

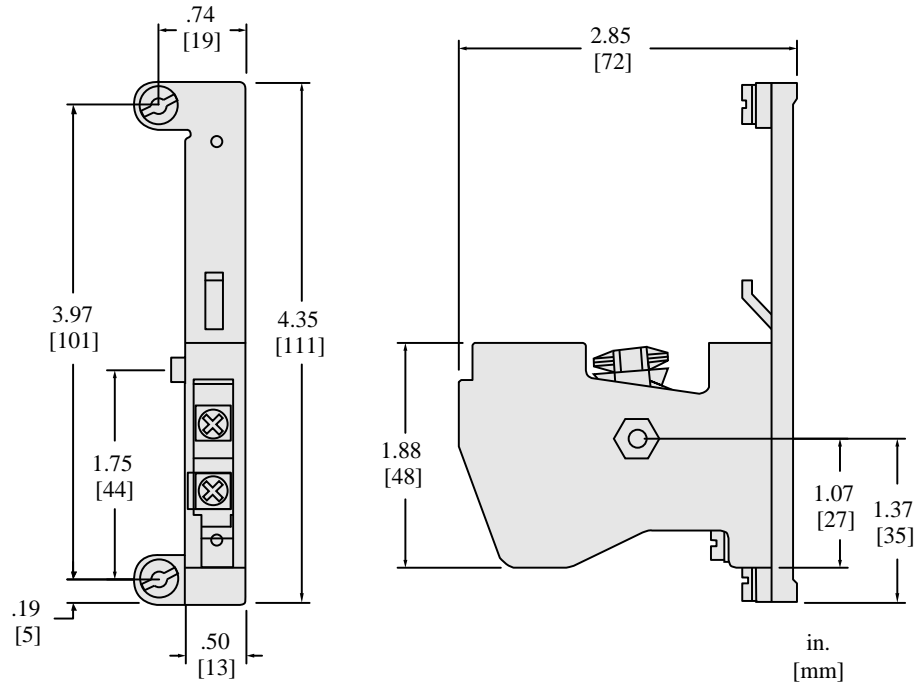

Auxiliary Contact Block

| NEMA CONTACTOR SIZE | NO. OF POWER POLES OF BASIC CONTACTOR | MAX. NO. OF EXTERNAL AUX. UNITS. (INTERNAL OR EXT.) |
|---------------------|---------------------------------------|---|
| 0, 1, and 2 | 1, 2, or 3 | 4 SINGLE CIRCUIT (N.O. OR N.C.) |
| | | 3 SINGLE CIRCUIT (N.O. OR N.C.) PLUS 1 TIMER (ON OR OFF DELAY) |
| | | 2 SINGLE CIRCUIT (N.O. OR N.C.) PLUS 1 POWER POLE (1 OR 2 N.O. OR N.C.) |
| | | 1 ATTACHED TIMER (ON OR OFF DELAY) PLUS 1 AUX CONTACT |
| | 4 or 5 | 2 SINGLE CIRCUIT (N.O. OR N.C.) PLUS 1 TIMER PLUS 1 AUX |

Dimensions are approximate. Refer to technical documentation for additional detail.