

Product data sheet


Characteristics

LX9FF220

TeSys F - specific contactor coil - 220...230 V AC
40...400 Hz low consumption

Product availability: Stock - Normally stocked in distribution facility

Price*: 92.66 USD

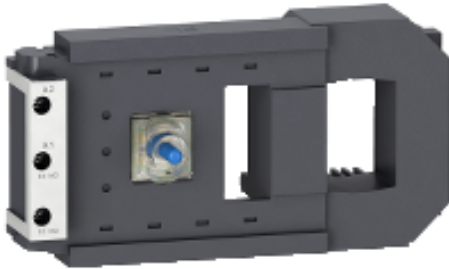

Main

Range	TeSys
Product or Component Type	Specific contactor coil
Device short name	LX9FF
Range compatibility	TeSys TeSys F LC1F contactor
Product Compatibility	LC1F115 LC1F150
Control circuit type	AC 40...400 Hz low consumption
[Uc] control circuit voltage	220...230 V AC 40...400 Hz
Inductance of closed circuit	7.7 H
Average resistance	59.4 Ohm inrush 68 °F (20 °C) 2190 Ohm holding 68 °F (20 °C)
Operating time	130 ms opening 35 ms closing
Mechanical durability	10 Mcycles
Maximum operating rate	2400 Cyc/H 131 °F (55 °C)

Complementary

Coil technology	Without built-in suppressor module
Control circuit voltage limits	Operational 0.85...1.1 Uc 131 °F (55 °C)) Drop-out 0.2...0.55 Uc 131 °F (55 °C))
Inrush power in VA	690...855 VA 40...400 Hz (at 68 °F (20 °C))
Hold-in power consumption in VA	6.6...8.1 VA 40...400 Hz (at 68 °F (20 °C))
Heat dissipation	5.9...7.2 W

Environment

Ambient air temperature for operation	23...131 °F (-5...55 °C)
Net Weight	0.95 Lb(US) (0.43 kg)

Ordering and shipping details

Category	US1011222341
Discount Schedule	0112
GTIN	3389110083941
Returnability	Yes
Country of origin	CZ

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.87 In (7.3 cm)
Package 1 Width	3.94 In (10 cm)
Package 1 Length	7.01 In (17.8 cm)
Package 1 Weight	18.5 Oz (524 g)
Unit Type of Package 2	S03
Number of Units in Package 2	14
Package 2 Height	11.81 In (30 cm)
Package 2 Width	11.81 In (30 cm)
Package 2 Length	15.75 In (40 cm)
Package 2 Weight	17.117 Lb(US) (7.764 kg)

Environmental data

Packaging without single use plastic	No
Packaging made with recycled cardboard	No
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information
Take-back	No

Contractual warranty

Warranty	18 months
----------	-----------

Product Life Status : **End of commerc. announced**