


# BCPMSCCT1

## BCPM 100A split-core CTs - set of 6 - 1.8m lead lengths

Product availability : Non-Stock - Not normally stocked in distribution facility

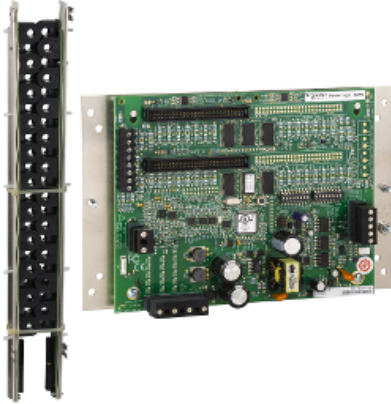

### Main

Range	PowerLogic
Product or component type	Current transformer
Electrical connection	Cable 5.91 ft (1.8 m)600 V
Line Rated Current	100 A

### Complementary

Product destination	BCPMSC
Current transformer type	Split core balance
Network frequency	50/60 Hz
Quantity per set	Set of 6
Width	Internal 0.63 in (16 mm) External 1.57 in (40 mm)
Depth	1.54 in (39 mm)
Height	Internal 0.79 in (20 mm) External 2.09 in (53 mm)

### Environment

Ambient air temperature for operation	32...140 °F (0...60 °C)
---------------------------------------	-------------------------

### Ordering and shipping details

Category	09793 - PLOGIC BRANCH CIRCUIT BCPM & MCM
Discount Schedule	PL1
GTIN	03606480344312
Nbr. of units in pkg.	1
Package weight(Lbs)	1.4 lb(US) (0.64 kg)
Returnability	No
Country of origin	CN

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

## Packing Units

Package 1 Height	2.24 in (57.000 mm)
Package 1 width	7.99 in (203.000 mm)
Package 1 Length	10.51 in (267.000 mm)

## Offer Sustainability

California proposition 65	WARNING: Cancer and Reproductive Harm - <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
RECh Regulation	<a href="#">RECh Declaration</a>
RECh free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.