


GS1AM110

Auxiliary contacts, TeSys GS, 1 NO, early break, front mounting, for GS2 with front/side handle

Product availability : Stock - Normally stocked in distribution facility

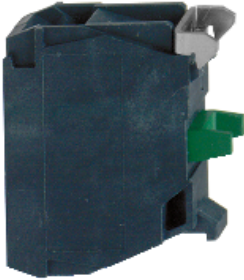

Main

Range of product	TeSys
Device short name	GS1AM
Product or component type	Auxiliary contact
Contact application	O, I and test position signalling
Range compatibility	TeSys GS fuse-switch disconnecter FuPact GS fuse-switch disconnecter
Contacts type and composition	1 NO
Contact operation	Early-break
[I _{th}] conventional free air thermal current	10 A 104 °F (40 °C)
[I _e] rated operational current	6 A 120 V AC-15 3 A 240 V AC-15 1.8 A 400 V AC-15 1.5 A 480 V AC-15 2.8 A 24 V DC-13 1.4 A 48 V DC-13 0.55 A 125 V DC-13 0.27 A 250 V DC-13 0.15 A 400 V DC-13

Complementary

Mechanical durability	5 Mcycles
Electrical durability	1 Mcycles AC-15
Switch rated current	30 A 32 A 50 A 60 A 63 A 100 A 125 A 160 A 200 A 250 A 315 A 400 A 600 A

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

	630 A 800 A 1250 A
Fuse type	NFC DIN BS CC J
Type of operating handle	External frontal External right side External left side
Mounting location	Front face
Net Weight	0.03 lb(US) (0.015 kg)

Ordering and shipping details

Category	22640 - IEC DISCONNECT-GS1,LK3
Discount Schedule	I11
GTIN	00785901367741
Nbr. of units in pkg.	1
Package weight(Lbs)	0.03 lb(US) (0.01 kg)
Returnability	Yes
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.79 in (2 cm)
Package 1 width	3.15 in (8 cm)
Package 1 Length	3.54 in (9 cm)
Package 2 Weight	26.74 oz (758 g)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Styrene, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov
RECh Regulation	RECh Declaration
RECh free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration

Contractual warranty

Warranty	18 months
----------	-----------