


Product availability : Stock - Normally stocked in distribution facility

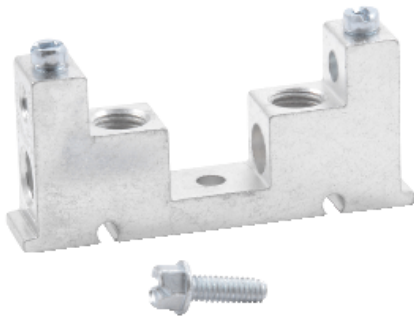

### Main

Range of product	Square D
Product or component type	Safety switch grounding bar
Series name	Heavy duty

### Complementary

Line Rated Current	60 A F1 60 A F3 60 A F5 60 A F7 100 A F2 100 A F7
AWG gauge	AWG 2 copper or aluminium
Width	3.180 in (80.77 mm)
Height	1.405 in (35.69 mm)
Depth	0.625 in (15.88 mm)
Tightening torque	20 lbf.in (2.26 N.m) AWG 14...AWG 10) 25 lbf.in (2.82 N.m) AWG 8) 35 lbf.in (3.95 N.m) AWG 6...AWG 4) 50 lbf.in (5.65 N.m) AWG 3...AWG 1/0)

### Ordering and shipping details

Category	00058 - MISC SWITCH ACCESSORIES
Discount Schedule	DE1
GTIN	00785901751380
Nbr. of units in pkg.	5
Package weight(Lbs)	0.15 lb(US) (0.07 kg)
Returnability	Yes

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Country of origin	US
-------------------	----

### Packing Units

Package 1 Height	0.60 in (1.524 cm)
Package 1 width	1.60 in (4.064 cm)
Package 1 Length	3.20 in (8.128 cm)

### Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

### Contractual warranty

Warranty	18 months
----------	-----------