


Product data sheet

Characteristics

HCM14486

Interior, I-Line PNLBRD, hcm, 600 A, main lugs,
32x48x8.25 in

Product availability : Stock - Normally stocked in distribution facility

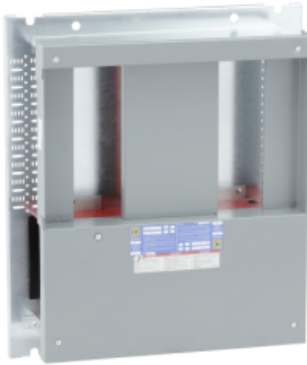

Main

Range	I-Line
-------	--------

Complementary

Main Type	Main lugs
Width	26.38 in (670.05 mm)
Height	30 in (762.00 mm)
Depth	7.66 in (194.56 mm)
Product Destination	Panelboard interior HCM 32 in (812.80 mm) 48 in (1219.20 mm) 8.25 in (209.55 mm)
Rated Current	600 A
Mounting Space	27 in (685.80 mm)
Net Weight	94.01 lb(US) (42.64 kg)

Ordering and shipping details

Category	00016 - I-LINE PB RTA
Discount Schedule	PE1A
GTIN	00785901780649
Package weight(Lbs)	87 lb(US) (39.46 kg)
Returnability	Yes
Country of origin	US

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Bisphenol A (BPA), which is known to the

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov

REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------