


Product availability : Stock - Normally stocked in distribution facility

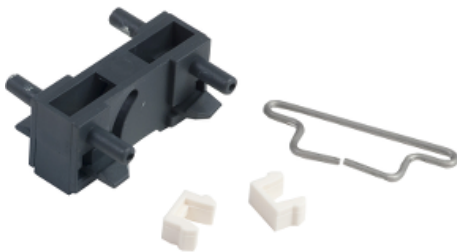

Main

Range of product	TeSys D
Range	TeSys
Device short name	LAD9
Product or component type	Mechanical interlock
Accessory / separate part category	Interlocking accessory
Interlocking type	Mechanical
Poles description	3P 4P
Electrical circuit type	Reversing Changeover
Range compatibility	TeSys D contactor
Product compatibility	LC1D09 LC1D12 LC1D18 LC1D25 LC1D32 LC1D38 LC1DT20 LC1DT25 LC1DT32 LC1DT40

Complementary

Net Weight	0.09 lb(US) (0.04 kg)
------------	-----------------------

Ordering and shipping details

Category	22354 - CTR, TESYS D, OPEN, 9-38A AC
Discount Schedule	I12

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

GTIN	00785901428770
Nbr. of units in pkg.	1
Package weight(Lbs)	0.01 lb(US) (0.00 kg)
Returnability	Yes
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	0.79 in (2 cm)
Package 1 width	3.15 in (8 cm)
Package 1 Length	4.37 in (11.1 cm)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	4.87 oz (138 g)
Package 2 Height	3.74 in (9.5 cm)
Package 2 width	3.94 in (10 cm)
Package 2 Length	5.98 in (15.2 cm)
Unit Type of Package 3	S03
Number of Units in Package 3	140
Package 3 Weight	5.20 lb(US) (2.359 kg)
Package 3 Height	11.81 in (30 cm)
Package 3 width	11.81 in (30 cm)
Package 3 Length	15.75 in (40 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------