


Product availability : Stock - Normally stocked in distribution facility

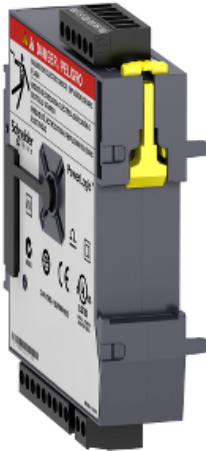

Main

Range	PowerLogic
Product or component type	I/O module
Device application	Optional expansion module
Range compatibility	PowerLogic PM8000 PowerLogic ION7400 PowerLogic ION9000

Complementary

Number of outputs	2 form C relay output
Number of inputs	6 digital
Width	0.87 in (22 mm)
Depth	3.56 in (90.5 mm)
Height	3.56 in (90.5 mm)
Net Weight	4.94 oz (140 g)

Environment

Ambient air temperature for operation	-13...158 °F (-25...70 °C)
Ambient air temperature for storage	-40...185 °F (-40...85 °C)
IP degree of protection	IP30 conforming to IEC 60529

Ordering and shipping details

Category	09782 - POWERLOGIC PM8000 ACCESSORIES
Discount Schedule	PL1
GTIN	00785901633402
Nbr. of units in pkg.	1

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Package weight(Lbs)	0.49 lb(US) (0.22 kg)
Returnability	Yes
Country of origin	CN

Packing Units

Package 1 Height	0.87 in (22.000 mm)
Package 1 width	3.56 in (90.500 mm)
Package 1 Length	3.56 in (90.500 mm)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.