

Product availability : Stock - Normally stocked in distribution facility



### Main

Product	Enclosure
---------	-----------

### Complementary

Material	Steel
Height	32 in (812.80 mm)
Width	20 in (508.00 mm)
Depth	5.75 in (146.05 mm)

### Environment

Enclosure Rating	NEMA 1
Product certifications	CULus

### Ordering and shipping details

Category	07969 - RTA PANELBOARD BOX - STD NEMA 1
Discount Schedule	PE1A
GTIN	00785901027812
Nbr. of units in pkg.	1
Package weight(Lbs)	24.42 lb(US) (11.08 kg)
Returnability	Yes
Country of origin	US

### Packing Units

Package 1 Height	6.00 in (15.240 cm)
Package 1 width	20.10 in (51.054 cm)
Package 1 Length	32.00 in (81.280 cm)

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.


## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

## Contractual warranty

Warranty	18 months
----------	-----------

Approximate Dimensions

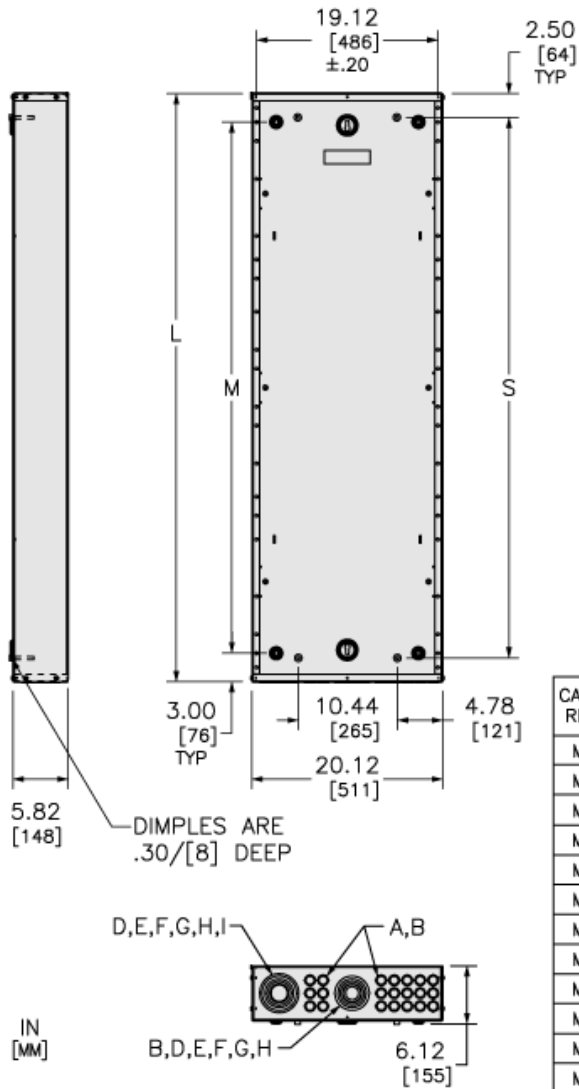

KNOCKOUTS				
SYMBOL	CONDUIT SIZE		KNOCKOUT DIA	
	IN	MM	IN	MM
A	.50	13	.88	22
B	.75	19	1.12	28
D	1.25	32	1.75	44
E	1.50	38	2.00	51
F	2.00	51	2.50	64
G	2.50	64	3.00	76
H	3.00	76	3.62	92
I	3.50	89	4.12	105

CATALOG REF NO	L		S		M	
	IN	MM	IN	MM	IN	MM
MH26	26.00	660	21.00	533	20.00	508
MH32	32.00	813	27.00	686	26.00	660
MH38	38.00	965	33.00	838	32.00	813
MH44	44.00	1118	39.00	991	38.00	965
MH50	50.00	1270	45.00	1143	44.00	1118
MH56	56.00	1422	51.00	1295	50.00	1270
MH62	62.00	1575	57.00	1448	56.00	1422
MH68	68.00	1727	63.00	1600	62.00	1575
MH74	74.00	1880	69.00	1753	68.00	1727
MH80	80.00	2032	75.00	1905	74.00	1880
MH86	86.00	2184	81.00	2057	80.00	2032
MH92	92.00	2337	87.00	2210	86.00	2184