

# Product data sheet

## Characteristics

# QO2100

Mini circuit breaker, QO, 100A, 2 pole, 120/240 VAC, 10 kA, plug in mount

Product availability : Stock - Normally stocked in distribution facility



### Main

Product	Miniature circuit-breaker
Range	QO
Current Rating	100 A
Voltage Rating	120/240 V AC 120 V AC
Mounting Type	Plug-in
Number of Poles	2P
Circuit Breaker Type	Standard
Ratings	HACR rated
Electrical Connection	Box lugs

### Complementary

Interrupt Rating	10 kA 120/240 V AC 50/60 Hz 10 kA 120 V AC 50/60 Hz
Number of Panel Spaces	2
Wire Size	AWG 4...AWG 2/0 copper or aluminium
Tightening Torque	40.71 lbf.in (4.6 N.m)
Height	3.5 in (88.90 mm)
Width	1.5 in (38.10 mm)
Depth	2.91 in (73.91 mm)

### Environment

Certifications	UL Listed CSA
Ambient Rating	104 °F (40 °C)

\* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

## Ordering and shipping details

Category	00104 - QO 35-70A 1P;70-125A 2P CB
Discount Schedule	DE2A
GTIN	00785901501305
Nbr. of units in pkg.	1
Package weight(Lbs)	0.71 lb(US) (0.32 kg)
Returnability	Yes
Country of origin	MX

## Packing Units

Package 1 Height	1.60 in (4.064 cm)
Package 1 width	3.40 in (8.636 cm)
Package 1 Length	3.80 in (9.652 cm)


## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Halogen content performance	Halogen free product

## Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

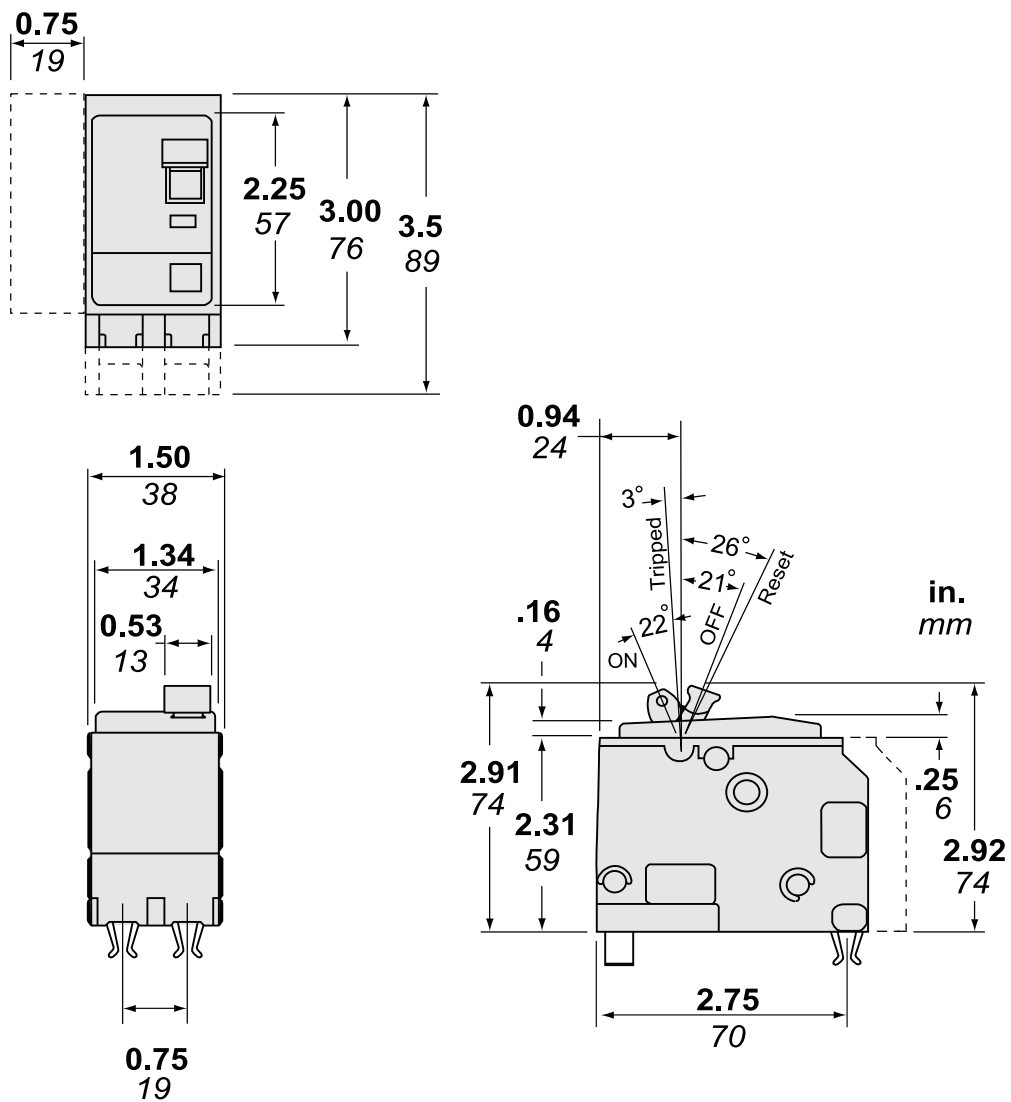

Dimensions are approximate. Refer to technical documentation for additional detail.