



Main

Range of product	Harmony Relay
Product or component type	Socket
Contact terminal arrangement	Separate

Complementary

Product compatibility	Plug-in relay RXG 1 C/O
[Ui] rated insulation voltage	250 V
[Uimp] rated impulse withstand voltage	6 kV
Line Rated Current	10 A
[Ue] rated operational voltage	250 V IEC 300 V UL
Connections - terminals	Screw terminals, 1 x 0.25...1 x 2.5 mm ² AWG 22...AWG 14) flexible with cable end Screw terminals, 2 x 0.25...2 x 1 mm ² AWG 22...AWG 17) flexible with cable end Screw terminals, 2 x 0.5...2 x 1.5 mm ² AWG 20...AWG 16) solid without cable end Screw terminals, 1 x 0.5...1 x 2.5 mm ² AWG 20...AWG 14) solid without cable end
Screw type	M3

Environment

Ambient air temperature for storage	-40...185 °F (-40...85 °C)
Ambient air temperature for operation	-40...158 °F (-40...70 °C)
Relative humidity	10...85 %
Standards	UL 508 CSA C22.2 No 14 IEC 61984
Product certifications	CE EAC RoHS

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

China RoHS
REACH
UL
CSA

IP degree of protection	IP20
Overvoltage category	III
Pollution degree	3

Ordering and shipping details

Category	21128 - ZELIO ICE CUBE RELAY ACCESSORIES
Discount Schedule	CP2
GTIN	00785901412151
Nbr. of units in pkg.	10
Package weight(Lbs)	0.09 lb(US) (0.04 kg)
Returnability	Yes
Country of origin	CN


Packing Units

Package 1 Height	2.44 in (62.000 mm)
Package 1 width	0.62 in (15.800 mm)
Package 1 Length	3.03 in (77.000 mm)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile

Dimensions

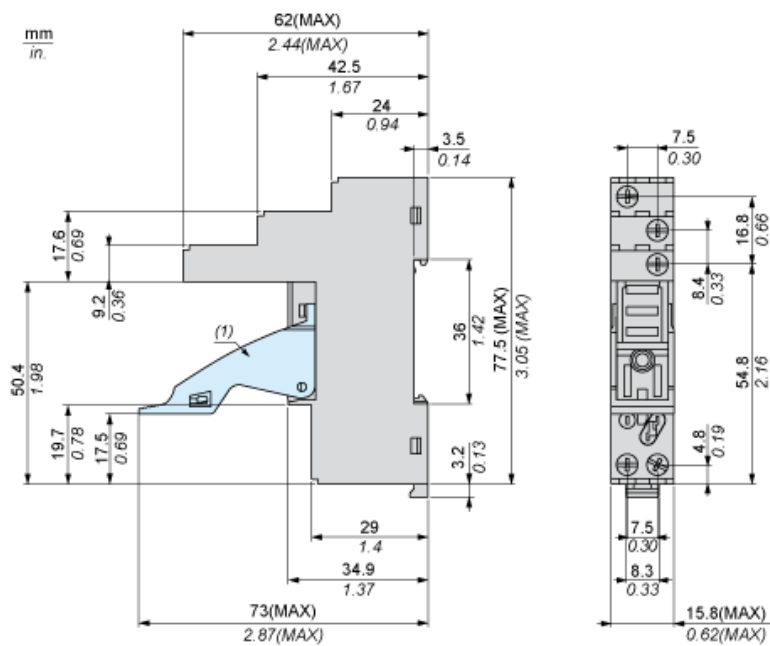

(1) Maintaining clamp

Wiring Diagram

